




Fibre optic diffuse reflection sensor

FT-30-P-A-R8/2m

Article no longer available - archive entry

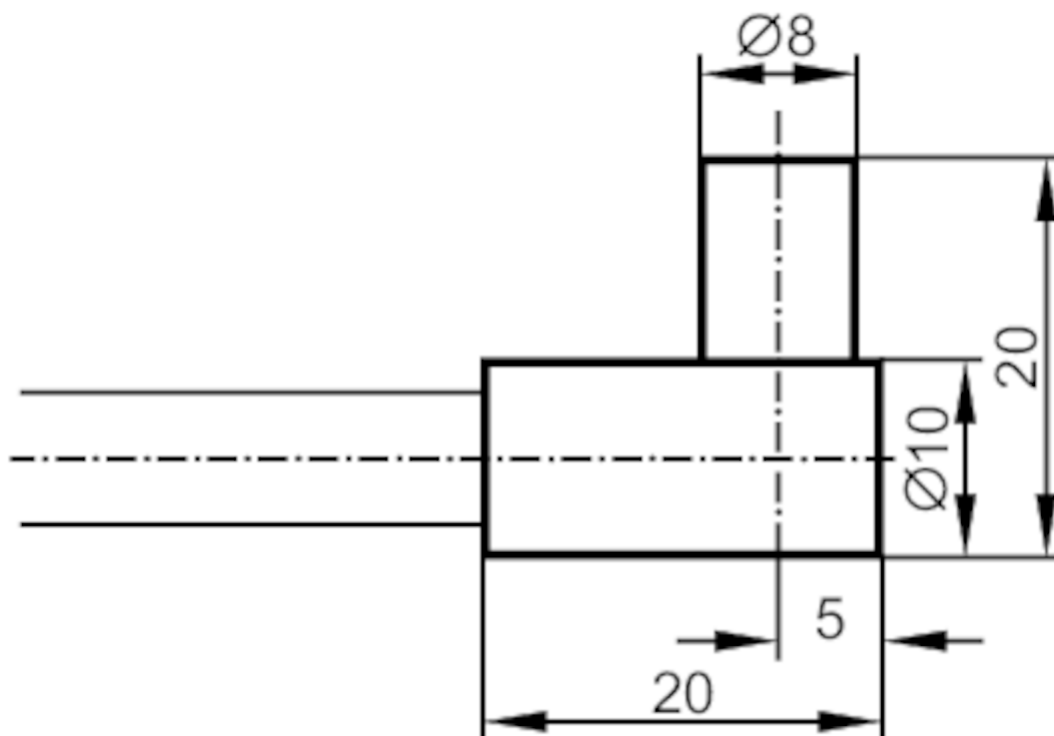

Application

Function principle

Diffuse reflection sensor

Detection zone

Range with fibre optic amplifier type

OIF

OIF

Range fibre optics

[mm]

56

Operating conditions

Ambient temperature

[°C]

-20...80

Mechanical data

Version of sensing head

angled

Total length

[mm]

2000

Min. bending radius

[mm]

30

Materials

Adapter: PA

Fibre material

glass

Fibre head material

aluminium

Fibre sheath material

PVC

Remarks

Pack quantity

1 pcs.