

E20365




Fibre optic through-beam sensor

FE-00-A-A-R3/2m

Article no longer available - archive entry

Alternative articles: E20366
When selecting an alternative article and accessories please note that technical data may differ!

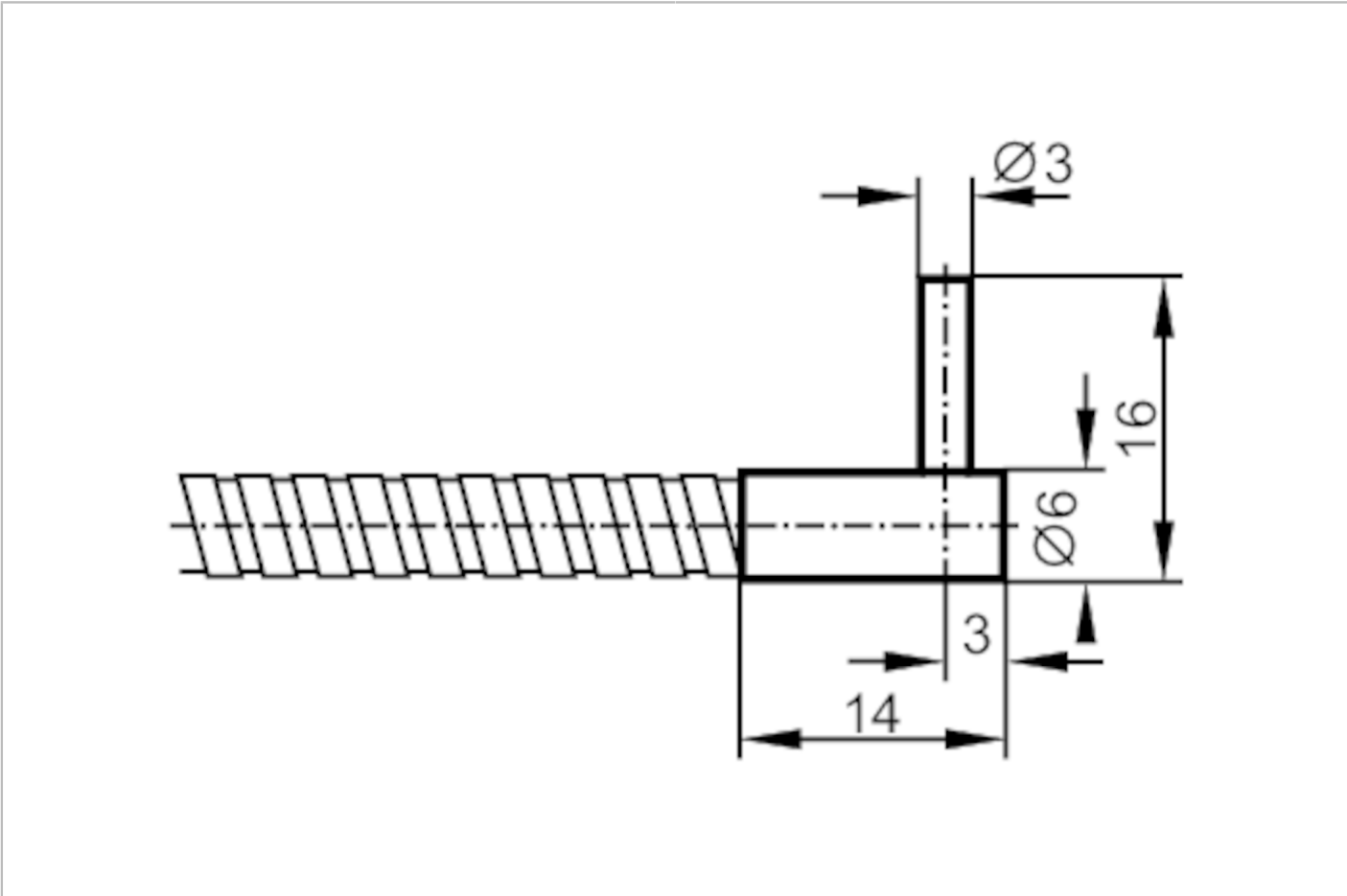

Application	
Function principle	Through-beam sensor
Detection zone	
Range with fibre-optic amplifier type	OKF; OUF
OKF	
Range of fibre optics [mm]	96
OUF	
Range of fibre optics [mm]	96
Operating conditions	
Ambient temperature [°C]	-40...290
Mechanical data	
Version of sensing head	angled
Sensing head diameter [mm]	3
Sensing head length [mm]	10
Total length [mm]	2000

E20365



Fibre optic through-beam sensor

FE-00-A-A-R3/2m

Min. bending radius	[mm]	20
Materials	Adapter: ABS	
Fibre material	glass	
Fibre head material	aluminium	
Fibre sheath material	aluminium	
Remarks		
Pack quantity	1 pcs.	