


Fibre optic through-beam sensor

FE-00-A-A-R3/2,5M

Article no longer available - archive entry

Alternative articles: E20129

When selecting an alternative article and accessories please note that technical data may differ!

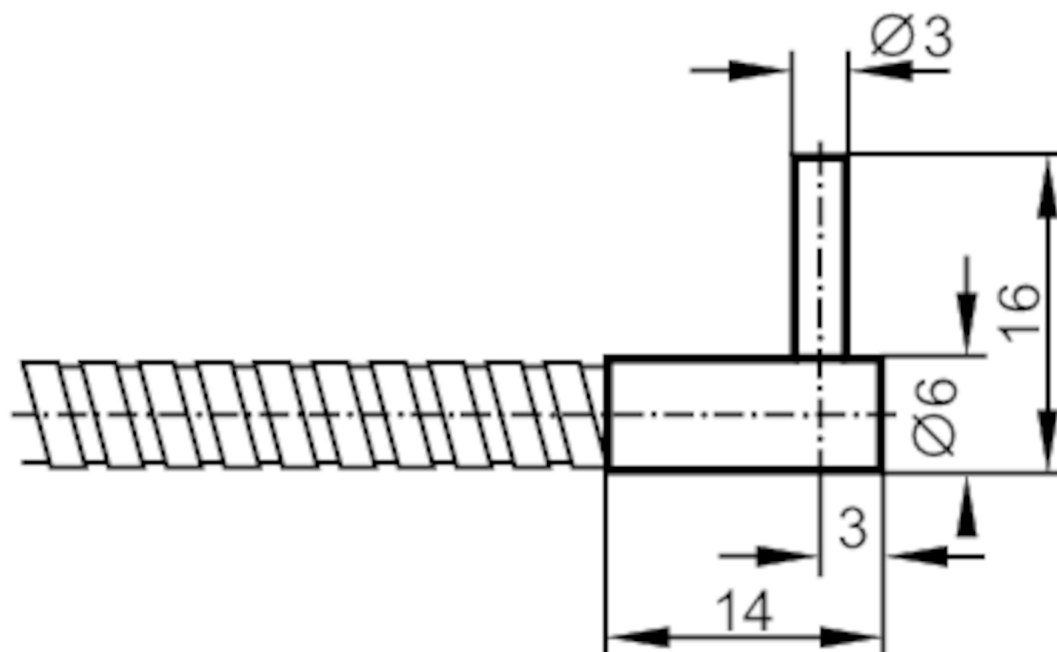

Application

Function principle	Through-beam sensor
--------------------	---------------------

Detection zone

Range with fibre-optic amplifier type	OKF; OUF
---------------------------------------	----------

OKF

Range of fibre optics [mm]	85
----------------------------	----

OUF

Range of fibre optics [mm]	85
----------------------------	----

Operating conditions

Ambient temperature [°C]	-40...290
--------------------------	-----------

Mechanical data

Version of sensing head	angled
Sensing head diameter [mm]	3
Sensing head length [mm]	10
Total length [mm]	2500

E20366



Fibre optic through-beam sensor

FE-00-A-A-R3/2,5M

Min. bending radius	[mm]	20
Materials		Adapter: ABS
Fibre material		glass
Fibre head material		aluminium
Fibre sheath material		aluminium
Remarks		
Pack quantity		1 pcs.