

E21036




Fibre optic diffuse reflection sensor

FT-11-M-V-M6/2M

Article no longer available - archive entry

Alternative articles: E21038

When selecting an alternative article and accessories please note that technical data may differ!

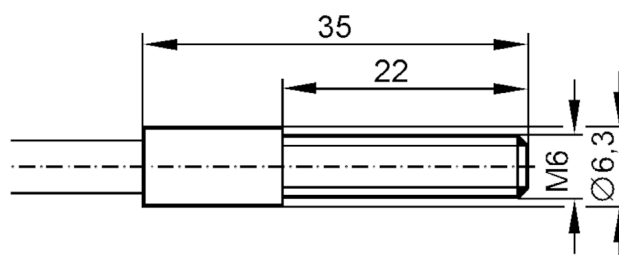

Application

Function principle Diffuse reflection sensor

Detection zone

Range with fibre optic amplifier type OB5030

OB50

Range fibre optics [mm] 40

Operating conditions

Ambient temperature [°C] -20...150

Mechanical data

Version of sensing head	straight
Sensing head thread	M6
Total length [mm]	600
Min. bending radius [mm]	20
Fibre material	glass
Fibre head material	stainless steel (1.4305 / 303)
Fibre sheath material	metal silicone

Remarks

Pack quantity 1 pcs.