


Connection cable

VDOGH040PL-0005A03STGH040MSS

Article no longer available - archive entry

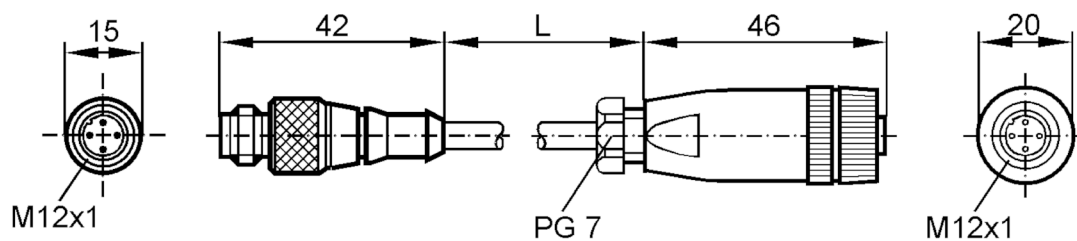

Electrical data

Operating voltage	[V]	10...36 DC
-------------------	-----	------------

Operating conditions

Ambient temperature	[°C]	-25...90
Protection		IP 67

Mechanical data

Dimensions	[mm]	15 x 15 x 42
Materials		TPU; PBT
Moulded-body material		TPU / PBT
Material nut		PBT / PA

Remarks

Pack quantity	1 pcs.
---------------	--------

Electrical connection - plug

Connector: 1 x M12, straight; coding: A; Moulded body: TPU / PBT; Locking: PBT



E70125




Connection cable

VDOGH040PL-0005A03STGH040MSS

Electrical connection

Cable: 5 m, PUR / PVC; 4 x 0.25 mm²

Connection

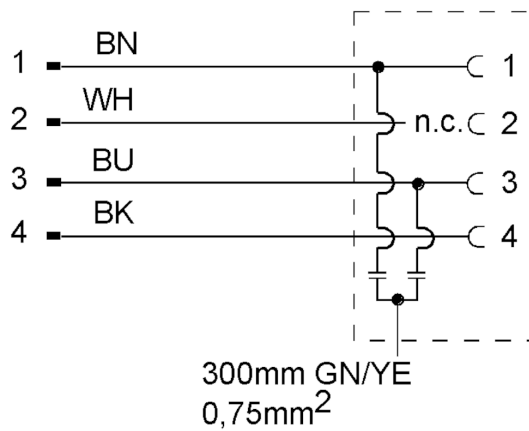

Electrical connection - socket

Connector: 1 x M12, straight; coding: A; Moulded body: TPU / PBT; Locking: PA

