

Diffuse reflection sensor

OGTLFPKG/B5/V4A/US-100

Article no longer available - archive entry

Alternative articles: OGH700

When selecting an alternative article and accessories please note that technical data may differ!



1 pushbutton

Product characteristics

Type of light	red light
Laser protection class	2
Housing	threaded type

Application

Special feature	Gold-plated contacts; Function check output
Function principle	Diffuse reflection sensor

Electrical data

Operating voltage	[V]	10...30 DC
Current consumption	[mA]	< 30; (operation; \$Einstellung: < 50 mA)
Protection class		II
Reverse polarity protection		yes
Type of light		red light
Wave length	[nm]	675
Typ. lifetime	[h]	50000

Outputs

Electrical design	PNP	
Output function	light-on/dark-on mode; (parameterisable)	
Max. voltage drop switching output DC	[V]	2.5
Function check output		yes
Max. voltage drop of function check output	[V]	3.5
Max. current load for function check output	[mA]	10
Permanent current rating of switching output DC	[mA]	200
Switching frequency DC	[Hz]	500



Diffuse reflection sensor

OGTLFPGK/B5/V4A/US-100

Short-circuit protection	yes	
Type of short-circuit protection	pulsed	
Overload protection	yes	
Detection zone		
Range [mm]	1...150; (white paper 200 x 200 mm 90% remission)	
Range adjustable	yes	
Max. light spot diameter [mm]	0.1	
Light spot dimensions refer to	Range	
Operating conditions		
Ambient temperature [°C]	-10...50	
Protection	IP 67	
Tests / approvals		
EMC	EN 60947-5-2	
	EN 55011	class B
Laser protection class	2	
Notes on laser protection	Caution:	laser light
	pulse performance:	<= 2,2 mW
	Wave length:	675 nm
	frequency:	2,2 kHz
	Pulse length:	24 µs
	Do not stare into beam.	
	Avoid exposure to the laser light.	
	laser class:	2
		EN 60825-1
Mechanical data		
Housing	threaded type	
Dimensions [mm]	M18 x 1 / L = 72	
Thread designation	M18 x 1	
Materials	stainless steel (316L/1.4404); PBT	
Lens material	PMMA	
Displays / operating elements		
Display	switching status	1 x LED, yellow
	operation	1 x LED, green
	function	1 x LED, red
Accessories		
Items supplied	lock nuts: 2	
Remarks		
Pack quantity	1 pcs.	

OG5056



Diffuse reflection sensor



OGTLFPGK/B5/V4A/US-100

Electrical connection

Connector: 1 x M12; coding: A; Contacts: gold-plated



Connection

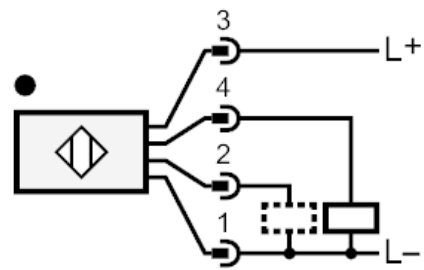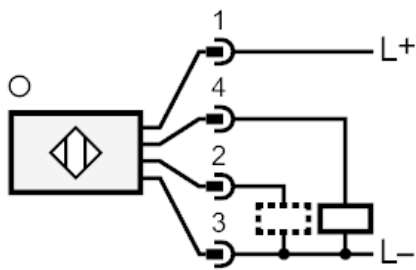

2 Function check output



Diffuse reflection sensor

OGTLFPGK/B5/V4A/US-100

Diagrams and graphs

excess gain graph

