




移動控制器的可接線插頭


BasicContact-Set/for CR0421

①

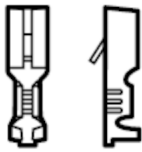


0,5...1,5 mm²

②

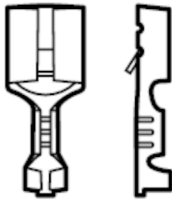


0,5...1,5 mm²

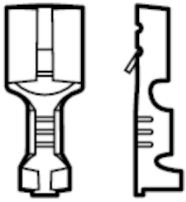


1,0...2,5 mm²

③

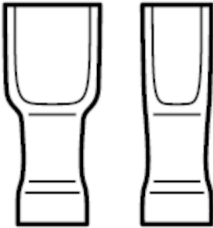


1,0...2,5 mm²

④

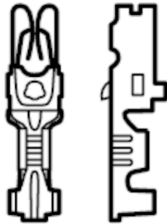


0,5...1,5 mm²

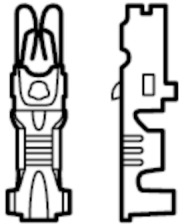


2,0...3,0 mm²

⑤

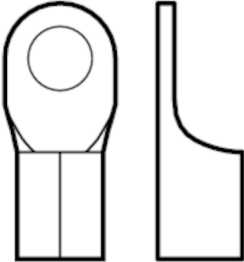

M6 (10 mm²)

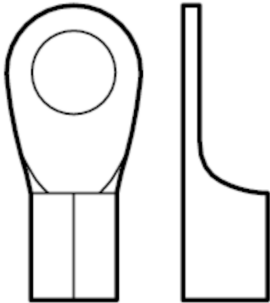

M8 (10 mm²)

1

鑷式插座 2.8 x 0.8 mm

2

鑷式插座 6.3 x 0.8 mm

3

鑷式插座 6.3 x 0.8 mm 完全絕緣

4

應用於車輛保險絲絕緣座的觸點

5

環形接線端

應用

設計

應用於BasicRelay, 連接BasicRelays, CR0421

機械技術數據

重量

[g]

85.5

尺寸

[mm]

134.5 x 50.6 x 210



移動控制器的可接線插頭

BasicContact-Set/for CR0421

附件

供貨範圍

應用於繼電器接點的刀片母接線端子: 10 x 2,8 x 0,8 mm (0,5...1,0 mm ²), DIN 46340
應用於繼電器接點的刀片母接線端子: 20 x 6,3 x 0,8 mm (0,5...1,0 mm ²), DIN 46340
應用於繼電器接點的刀片母接線端子: 20 x 6,3 x 0,8 mm (1,0...2,5 mm ²), DIN 46340
應用於電源分配器刀片母接線端子: 20 x 6,3 x 0,8 mm (1,0...2,5 mm ²), 完全絕緣 DIN 46245
應用於車輛保險絲絕緣座的觸點: 6 x 0,5...1,5 mm ²
應用於車輛保險絲絕緣座的觸點: 4 x 2,0...3,0 mm ²
應用於電源的環形接線端: 1 x M6 (10 mm ²), DIN 46234
應用於電源的環形接線端: 1 x M8 (10 mm ²), DIN 46234
螺母: 1 x M6, 鍍鋅的 ISO 4032
螺母: 1 x M8, 鍍鋅的 ISO 4032

電氣連接

接線端子座: