


## Lower part for AS-Interface module

EEMS-Base FC Address.socket

Article no longer available - archive entry

Alternative articles: AC5011

When selecting an alternative article and accessories please note that technical data may differ!

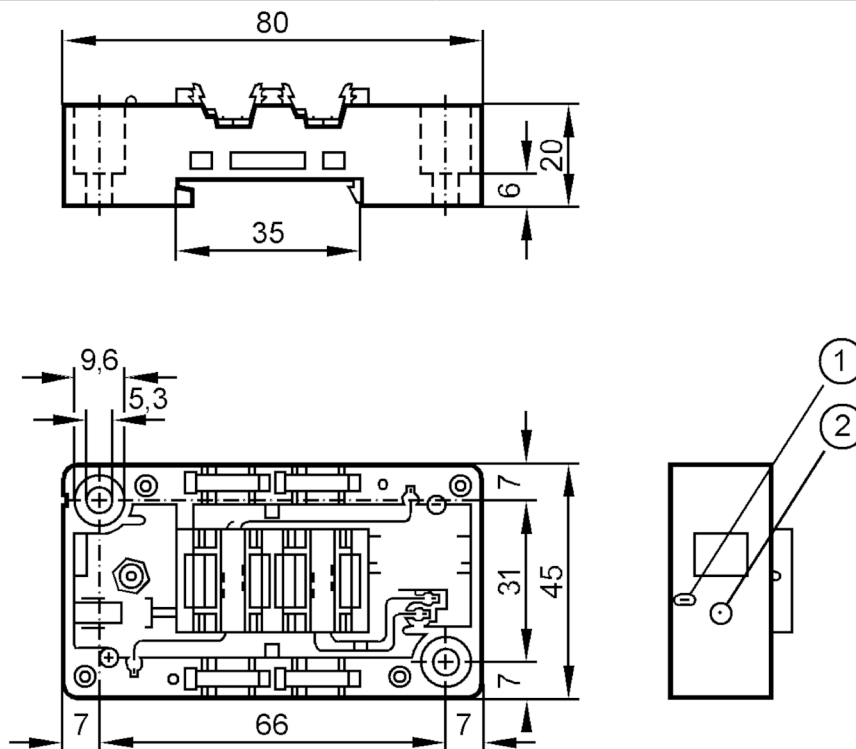

- 1 earthing lead  
2 addressing socket

**Electrical data**

Operating voltage	[V]	26.5...31.6 DC
Additional voltage supply	[V]	24 DC

**Outputs**

Electrical design	AS-i
Contact rating	< 2 A

**Operating conditions**

Ambient temperature	[°C]	-25...85
Protection	IP 67; (depending on the upper part used: IP 20 / IP 65 / IP 67)	

**AS-i classification**

AS-i addressing	addressing socket
-----------------	-------------------

**Mechanical data**

Housing	housing for DIN rail mounting
Dimensions [mm]	45 x 80 x 20
Materials	PBT

**Remarks**

Remarks	recommended sleeve for earthing lead: A 2.8 x 0.5 DIN 46247
	Module lower part can be used with upper parts where pin 5 of the M12 socket is connected to functional earth (FE).

# AC5023



## Lower part for AS-Interface module

EEMS-Base FC Address.socket

Pack quantity

1 pcs.

### Electrical connection

contact pins in module upper part :

quick mounting technology for AS-i flat cable: