


E10850



Connecting cable with socket

ADOGA030VAS0005E03

Article no longer available - archive entry

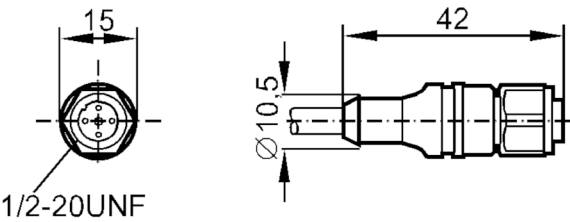

Application		
Special feature		Free from silicone; Gold-plated contacts
Free from silicone		yes
Electrical data		
Operating voltage	[V]	< 250 AC
Operating conditions		
Ambient temperature	[°C]	-25...70
Protection		IP 67
Mechanical data		
Dimensions	[mm]	15 x 15 x 42
Materials		PVC
Moulded-body material		PVC
Material nut		stainless steel (1.4404 / 316L)
Remarks		
Pack quantity		1 pcs.

E10850



Connecting cable with socket

ADOGA030VAS0005E03

Electrical connection


Cable: 5 m, PVC, yellow, Ø 5 mm; 3 x 0.38 mm² (19 x Ø 0.16 mm)

Electrical connection - socket

Connector: 1 x 1/2", straight; coding: C; Moulded body: PVC; Locking: stainless steel (1.4404 / 316L); Contacts: gold-plated



Connection

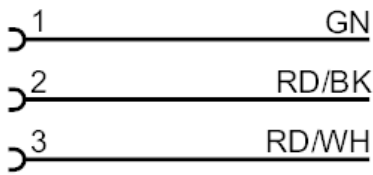

GN =	Core colours :
RD/BK =	green
RD/WH =	red/black
	red/white