


# E12572



## Connection cable for signal lamps with 8-pole connectors

VDOGH080MSS0001H04STGH040MSS

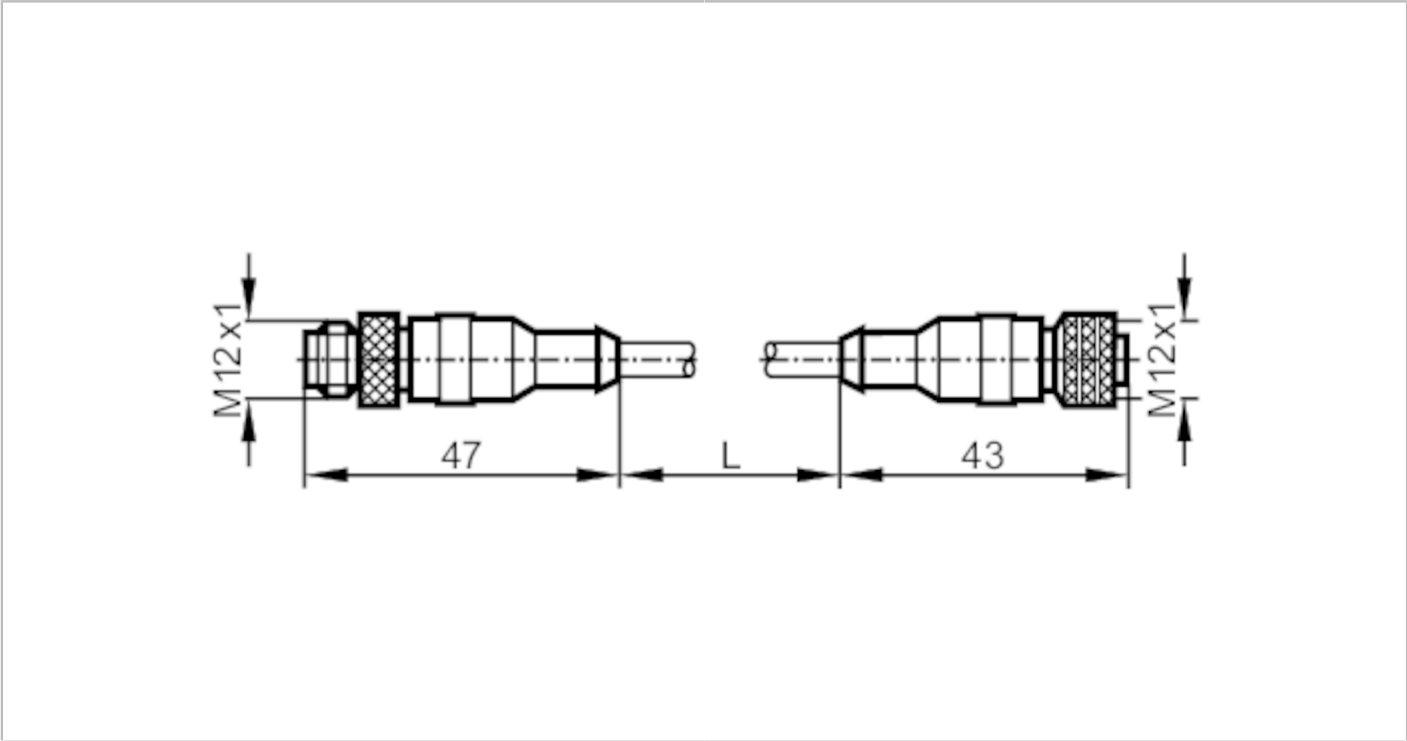

Application	
Special feature	Halogen-free
Application	cable to connect a light tower DV13xx & Dv15xx to an IO-Link master
Electrical data	
Operating voltage [V]	< 30 AC / < 36 DC
Operating conditions	
Ambient temperature [°C]	-25...80
Protection	IP 68
Mechanical data	
Weight [g]	51
Materials	PUR
Moulded-body material	PUR
Material nut	brass, nickel-plated
Remarks	
Pack quantity	1 pcs.



## Connection cable for signal lamps with 8-pole connectors

VDOGH080MSS0001H04STGH040MSS

### Electrical connection - plug


Connector: 1 x M12, straight; coding: A; Moulded body: PUR; Locking: brass, nickel-plated; Tightening torque: 0.7...0.9 Nm



### Electrical connection

Cable: 1 m, PUR, Halogen-free, black, Ø 6.8 mm; 3 x 0.25 mm<sup>2</sup>

### Connection

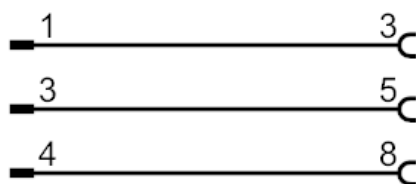

### Electrical connection - socket

Connector: 1 x M12, straight; coding: A; Moulded body: PUR; Locking: brass, nickel-plated; Tightening torque: 0.7...0.9 Nm

