


# E19902



## Y-splitter

ZDO2H045MSS0010B05

Article no longer available - archive entry

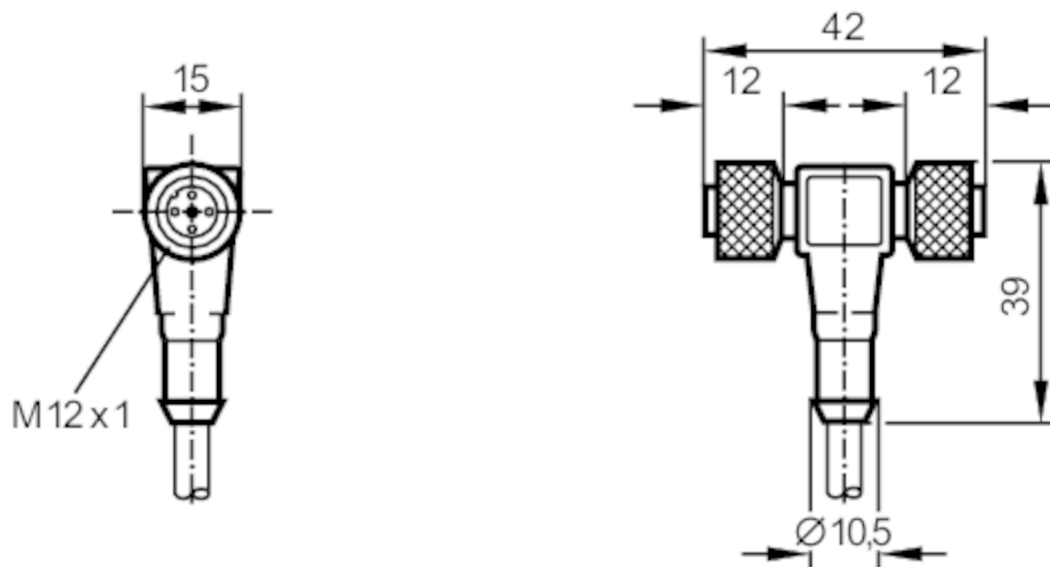

### Electrical data

Operating voltage	[V]	< 125 AC / < 150 DC
Max. current load per module/slot	[A]	4
Max. current load total	[A]	4

### Operating conditions

Ambient temperature	[°C]	-15...90
Protection		IP 67

### Mechanical data

Materials		TPU
-----------	--	-----

### Remarks

Pack quantity		1 pcs.
---------------	--	--------

# E19902




## Y-splitter

ZDO2H045MSS0010B05

### Electrical connection

Cable: 10 m, PUR / PVC, orange, Ø 5 mm; 4 x 0.25 mm<sup>2</sup> (32 x Ø 0.1 mm )

### Connection

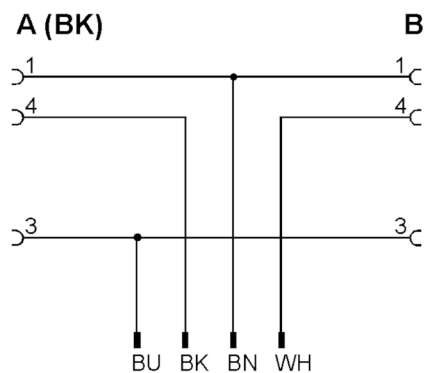

Core colours :

BK = black  
BN = brown  
BU = blue  
WH = white

Article no longer available - archive entry