




Fibre optic diffuse reflection sensor

FT-00-MPV-M6/1,2M

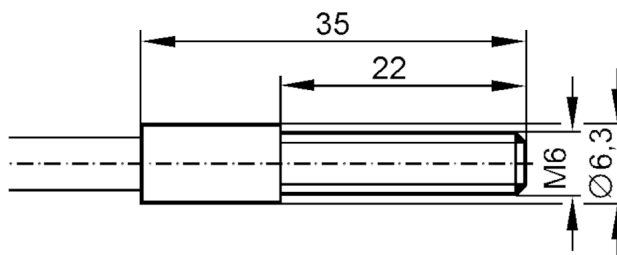

Application	
Function principle	Diffuse reflection sensor
Detection zone	
Range with fibre optic amplifier type	OKF; OUF
OKF	
Range fibre optics [mm]	15
OUF	
Range fibre optics [mm]	15
Operating conditions	
Ambient temperature [°C]	-20...80
Mechanical data	
Weight [g]	84.5
Version of sensing head	straight
Sensing head thread	M6
Total length [mm]	1200
Min. bending radius [mm]	20
Fibre arrangement	
Fibre material	PMMA
Fibre head material	stainless steel (1.4305 / 303)
Fibre sheath material	metal silicone
Accessories	
Accessories (supplied)	hexagon nuts: 4 x M6, stainless steel tooth lock washers: 2 knurled nut: 1 x M11

E20571



Fibre optic diffuse reflection sensor

FT-00-MPV-M6/1,2M

Remarks

Pack quantity

1 pcs.