


E21137



Ethernet connection cable

VSTGN040ZDS0010L04STGN040ZDS

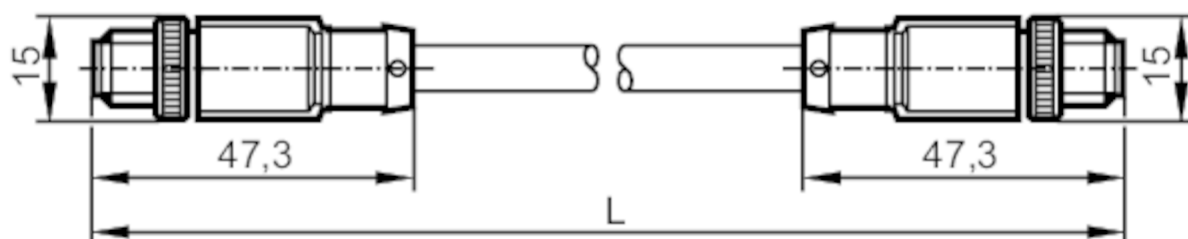

Application

Special feature	Gold-plated contacts; Screened cable
Design	Ethernet cable, D-coded

Electrical data

Operating voltage	[V]	< 50 AC / < 60 DC
Protection class		III
Max. current load total	[A]	4

Operating conditions

Ambient temperature	[°C]	-20...90
Protection		IP 67

Mechanical data

Weight	[g]	687
Dimensions	[mm]	15 x 15 x 47.3
Materials		TPU
Moulded-body material		TPU
Material nut		diecast zinc, nickel-plated

Remarks

Pack quantity		1 pcs.
---------------	--	--------

E21137



Ethernet connection cable

VSTGN040ZDS0010L04STGN040ZDS

Electrical connection - plug


Connector: 1 x M12, straight; coding: D; Moulded body: TPU; Locking: diecast zinc, nickel-plated; Contacts: gold-plated; Shielded connection cable: screen connected



Electrical connection

Cable: 10 m, PVC, green, shielded; 4 x 0.34 mm²

Connection

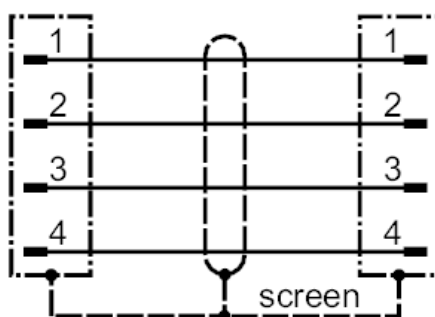

Electrical connection - plug

Connector: 1 x M12, straight; coding: D; Moulded body: TPU; Locking: diecast zinc, nickel-plated; Contacts: gold-plated; Shielded connection cable: screen connected

