


# E30080



## Plug-in power supply

POWER SUPPLY 24V IP40/IP67

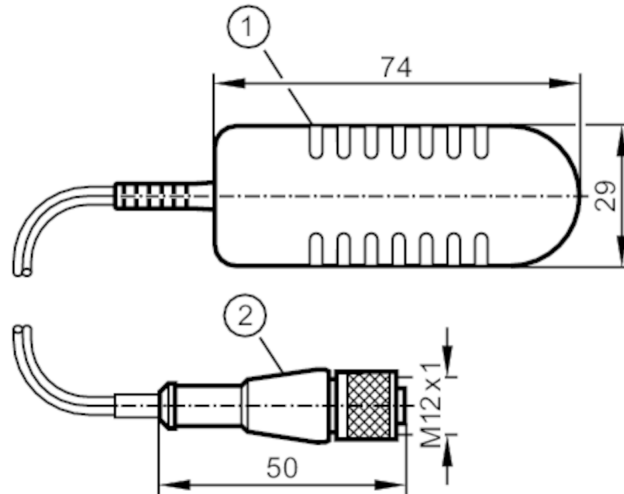

- 1 Power supply
- 2 M12 connector



Electrical data		
Nominal frequency AC	[Hz]	50...60
Input voltage AC	[V]	100...240
Output voltage DC	[V]	24
Input current (nominal voltage 230 V AC / 50 Hz)	[A]	0.2
Outputs		
Output current, total	[A]	0.33
Operating conditions		
Protection	IP 40; (M12 connector: IP 67)	
Mechanical data		
Weight	[g]	135
Materials	PPE	
Remarks		
Pack quantity	1 pcs.	
Electrical connection		
Cable: 2 m; 2 x 0.5 mm <sup>2</sup>		
Connector: 1 x M12		