


IO-Link interface

USB IO-LINK INTERFACE

Article no longer available - archive entry

Alternative articles: ZZ1060

When selecting an alternative article and accessories please note that technical data may differ!

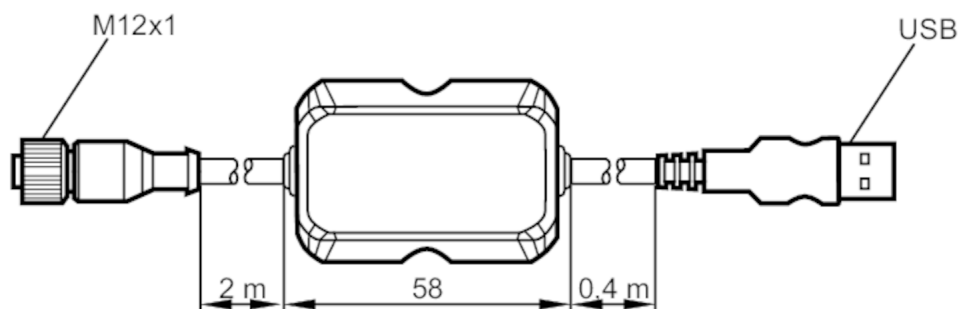

Application

Application	parameter setting and analysis of units with max. 65 mA current consumption
-------------	---

Electrical data

Input voltage DC	[V]	5
Output voltage DC	[V]	24

Outputs

Output current, total	[A]	0.065; (Sensor supply)
-----------------------	-----	------------------------

Operating conditions

Ambient temperature	[°C]	-25...45
---------------------	------	----------

Mechanical data

Weight	[g]	173.8
--------	-----	-------

Accessories


Accessories (optional)	Software: "LINERECORDER DEVICE", QA0011 / QA0012
------------------------	--

Remarks

Pack quantity	1 pcs.
---------------	--------

Electrical connection - IO-Link


Connector: M12; coding: A

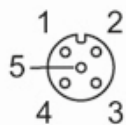

IO-Link interface

USB IO-LINK INTERFACE

Connection

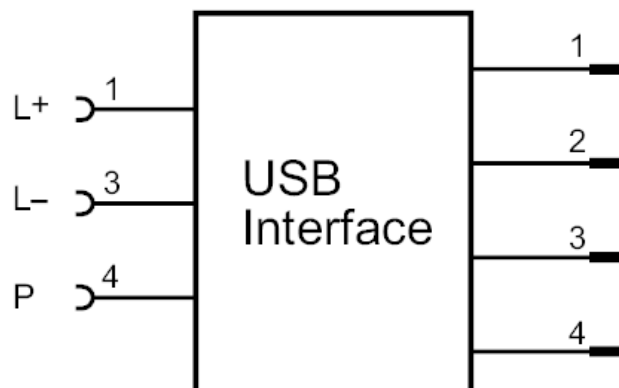

P = communication via IO-Link

Electrical connection - USB

Connector: USB

