




Combined antenna for navigation and radio

GSM/UMTS/HSPA/GPS Antenna

phase-out article

Alternative articles: EC3158

When selecting an alternative article and accessories please note that technical data may differ!

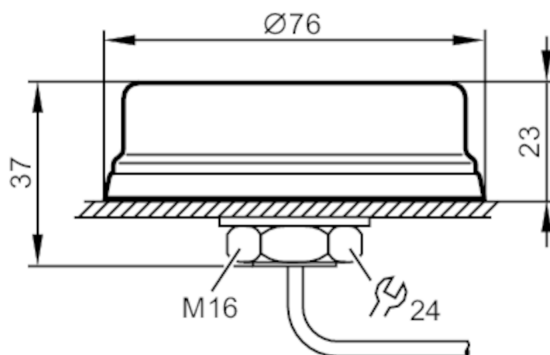

Electrical data

Operating voltage	[V]	via the internal wire of the GPS connection
Current consumption	[mA]	< 30

Operating conditions

Ambient temperature	[°C]	-40...85
Protection		IP 69K

Mechanical data

Weight	[g]	151.5
Type of mounting		Gewinde
Tightening torque	[Nm]	< 5

Remarks

Remarks	<p>When mounting the antenna(s) in vehicles avoid the vicinity of fuel tanks, vessels with explosives or insufficiently screened electronic components.</p> <p>Do not install antenna inside closed metal construction (e.g. in driver's cabin).</p> <p>Clean the mounting surface before the installation.</p> <p>Do not extend or shorten antenna cable.</p> <p>Avoid direct exposure to steam or high-pressure cleaning during car wash.</p> <p>Radio communication can affect the function of electronic devices that are not correctly shielded.</p> <p>Contact the manufacturer of the corresponding device in case of any interference.</p>
Pack quantity	1 pcs.

Electrical connection - GPS

Cable: 3 m

Connector: 1 x FAKRA

Electrical connection - GSM

Cable: 3 m

Connector: 1 x FAKRA