


# EVC699



## Connection cable

VDOG F040MSS01,5H03STGF030MSS

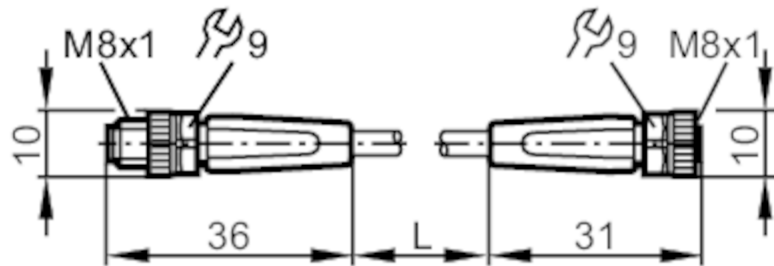

### Application

Free from silicone yes

### Electrical data

Operating voltage [V]	< 50 AC / < 60 DC
Protection class	III
Max. current load total [A]	3

### Operating conditions

Ambient temperature [°C]	-25...90
Note on ambient temperature	cULus: ...85
Ambient temperature (moving) [°C]	-25...90
Note on ambient temperature (moving)	cULus: ...85
Protection	IP 65; IP 67; IP 68; IP 69K

### Mechanical data

Weight [g]	49.5	
Materials	housing: TPU orange; Sealing: FKM	
Material nut	brass, nickel-plated / brass, nickel-plated	
Drag chain suitability	yes	
Drag chain suitability	bending radius for flexible use	min. 10 x cable diameter
	travel speed	max. 3.3 m/s for a horizontal travel length of 5 m and max. acceleration of 5 m/s <sup>2</sup>
	bending cycles	> 5 Mio.
	torsional strain	± 180 °/m

# EVC699



## Connection cable

VDOGF040MSS01,5H03STGF030MSS

### Remarks

Pack quantity

1 pcs.

### Electrical connection - plug


Connector: 1 x M8, straight; Locking: brass, nickel-plated; Contacts: gold-plated; Tightening torque: 0.3...0.5 Nm



### Electrical connection

Cable: 1.5 m, PUR, Halogen-free, black,  $\varnothing$  3.7 mm; 3 x 0.25 mm<sup>2</sup> (32 x  $\varnothing$  0.1 mm )

### Connection

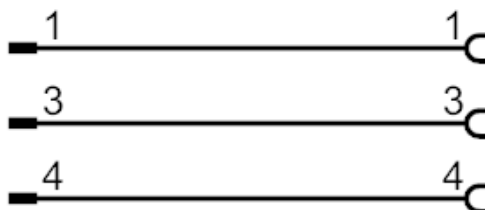

### Electrical connection - socket

Connector: 1 x M8, straight; Locking: brass, nickel-plated; Contacts: gold-plated; Tightening torque: 0.3...0.5 Nm

