


Spojni kabel

VDOAH043MSS0001F04STGH040MSS

Proizvod više nije dostupan – arhivski unos

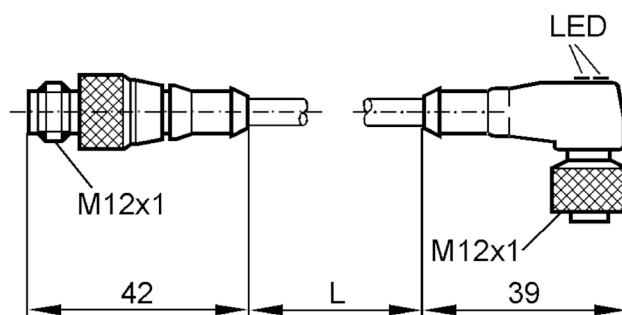

Električni podaci

Radni napon	[V]	10...30 DC
-------------	-----	------------

Radni uvjeti

Temperatura okoline	[°C]	-25...70
---------------------	------	----------

Zaštita	IP 67
---------	-------

Mehanički podaci

Materijali	TPU
------------	-----

Prikazi / radni elementi

Prikaz	Status prekapčanja	1 x LED, Žuto
	Pogon	1 x LED, Zeleno

Opaske

Količina pakiranja	1 kom.
--------------------	--------

E10832



Spojni kabel

VDOAH043MSS0001F04STGH040MSS

Električni priključak

Kabel: 1 m, PVC, Narančasto, Ø 5 mm; iradirano; 4 x 0,34 mm² (19 x Ø 0,15 mm)

Priključak

