


E11187

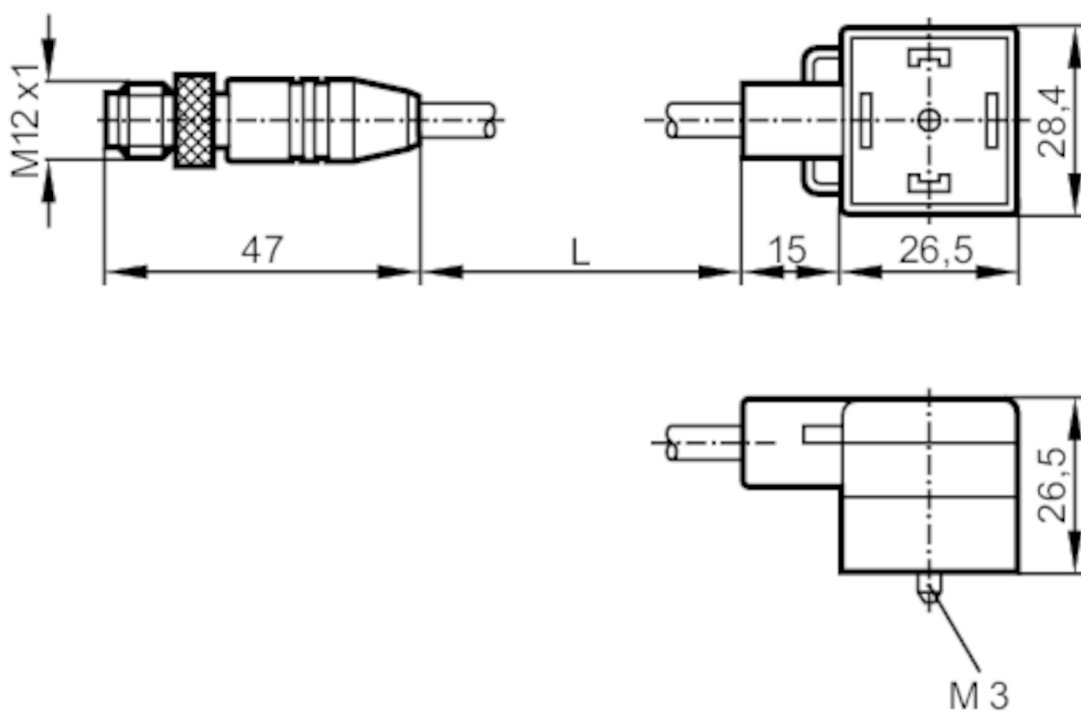

Premosni kabel s utikačem ventila

VVDAA040MSS0001H03STGH020MSS



Primjena

Primjena

mjerjenje struje

Električni podaci

Radni napon

[V]

< 24 AC/DC

Radni uvjeti

Temperatura okoline

[°C]

-40...90

Zaštita

IP 67; IP 69K

Mehanički podaci

Težina

[g]

99,4

Materijali

TPU

Materijal ulivenog tijela

TPU

Zaporna matica materijala

Mjed, niklovano

Dodatna oprema

Isporuka obuhvata

vijak

Ploča za etiketiranje

Opaske

Količina pakiranja

1 kom.



Premosni kabel s utikačem ventila

VVDAA040MSS0001H03STGH020MSS

Električni priključak - utikač

 
Poveznik: 1 x M12, ravno; kodiranje: A; Oblikovana karoserija: TPU; Zaključavanje: Mjed, niklovano; Zakretni moment pritezanja: 0,5 Nm



Električni priključak

Kabel: 1 m, PUR; 2 x 0,75 mm²

Priključak



Električni priključak - utičnica

Poveznik: 1 x ventil vrste A DIN, kutno; Oblikovana karoserija: TPU; Zaključavanje: Mjed, niklovano; Zakretni moment pritezanja: 0,5 Nm

