


E12274



Volumni kabel

CABLE/10M/ Silicon/4X0,34/BK

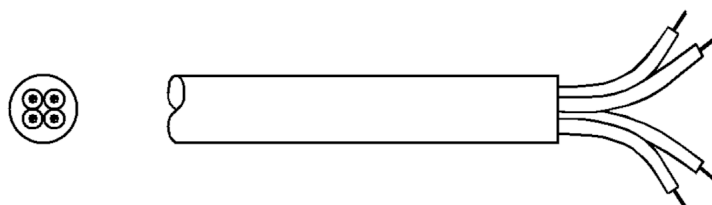

Radni uvjeti

Temperatura okoline	[°C]	-50...180
Temperatura okoline (pokretna)	[°C]	-30...180

Mehanički podaci

Težina	[g]	447,8
--------	-----	-------

Opaske

Količina pakiranja	1 kom.
--------------------	--------

Električni priključak

Kabel: 10 m, Silikon, crno, Ø 5,4 mm; 4 x 0,34 mm² (19 x Ø 0,15 mm), Silikon