


Zaštitna cijev za temperaturne senzore

THERMOWELL, D6/1,5"CLAMP/L=100

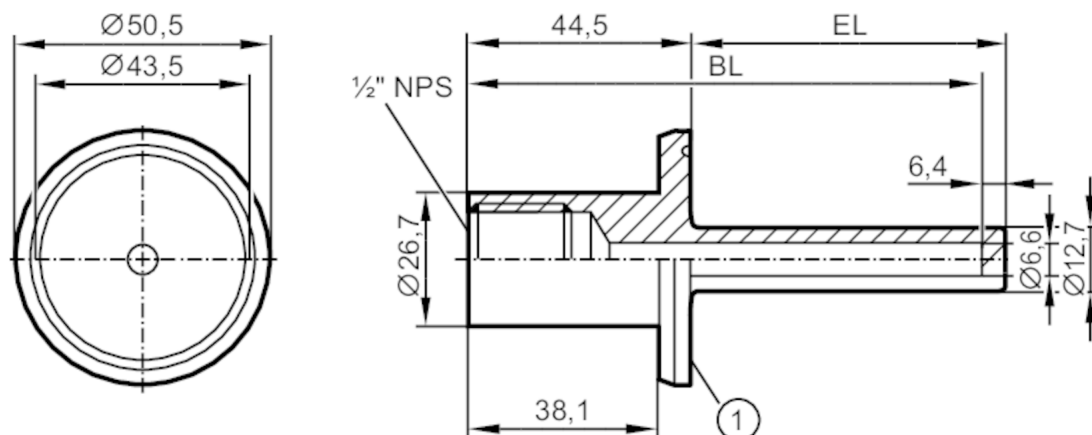

1 1,5" Clamp (ISO 2852)



EC 1935/2004 EHEDG Certified



Primjena

Dizajn za temperaturne senzore EL = 100 mm

Snaga tlaka [bar] 25

Mehanički podaci

Težina [g] 241

Materijali nehrđajući čelik (1,4404/316L)

Spajanje senzora 1/2" NPS Ø 6 mm prikladno za NPT G1/2 i 1/2" NPT

Procesni priključak Clamp DN25...DN40 (1...1,5") DIN 32676 (ISO 2852)

Površinske značajke Ra/Rz vlažnih dijelova $\leq 0,6 / -$

Duljina instalacije EL [mm] 64

Duljina provrta BL [mm] 101,6

Opaske

Količina pakiranja 1 kom.