


E78000



Adapter vodilice DIN

DIN rail adapter 3/4 rows

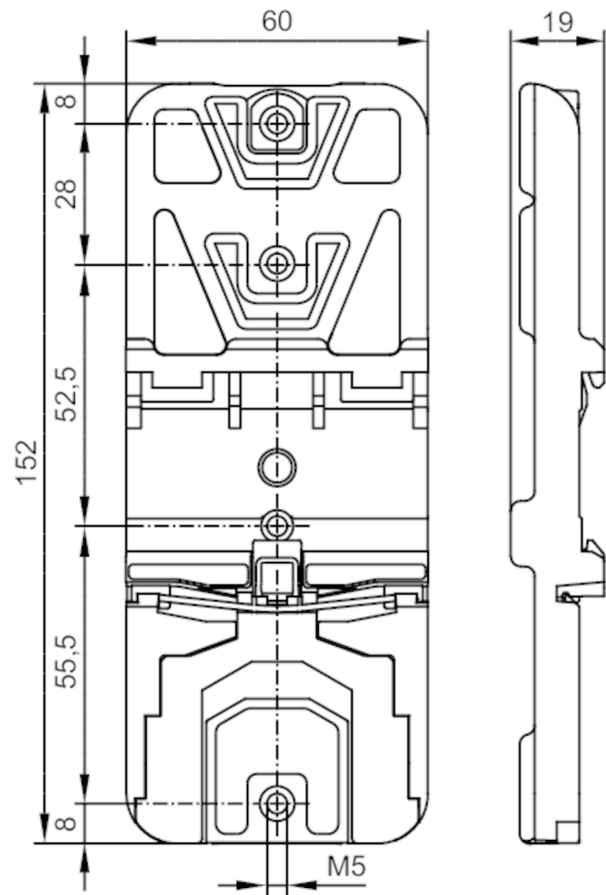

Primjena

Dizajn za postavljanje vodilice DIN, npr. masteri IO-Link 4-Port

Mehanički podaci

Težina [g]	87,6
Vrsta montaže	DIN šinsko montiranje
Dimenzije [mm]	152 x 60 x 19
Materijali	Adapter vodilice DIN: PC/ABS; uvodnica s navojem: nehrđajući čelik (1,4404/316L)

Dodatna oprema

Isporuka obuhvata	podloška 2 x M5
	vijak 2 x M5 x 30
	vijak 1 x M5 x 10

Opaske

Količina pakiranja	1 kom.
--------------------	--------