





Kabel spoja Y

Cable/Plug&Play/M12/0.6m

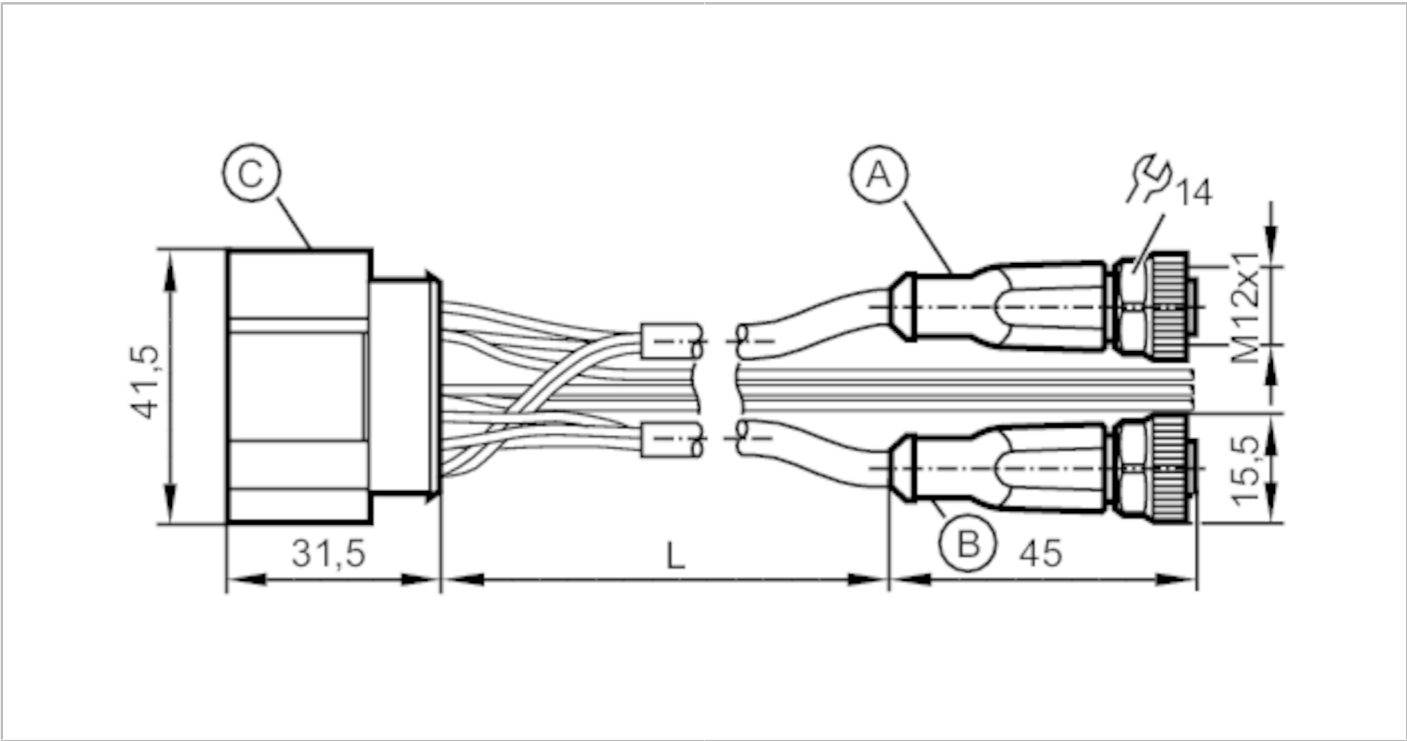

Primjena		
Dizajn		Kabel adaptera
Električni podaci		
Radni napon	[V]	8...32 DC
Radni uvjeti		
Temperatura okoline	[°C]	-20...85
Mehanički podaci		
Težina	[g]	109
Materijali		kućište: PBT crno; utičnica: TPU Narančasto; Brtva: Viton
Opaske		
Količina pakiranja		1 kom.
Električni priključak - C		

Poveznik: 1 x Konektor AMP-a, ravno

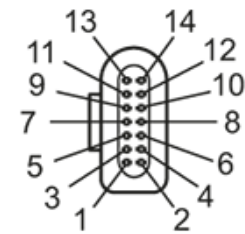

Električni priključak

Kabel: 0,6 m, PUR, crno, Ø 5,1 mm; 5 x 0,5 mm²

Kabel: 0,6 m, PUR, crno, Ø 4,9 mm; 3 x 0,5 mm²




Kabel spoja Y

Cable/Plug&Play/M12/0.6m


Kabel: 0,6 m; 2 x 0,5 mm²

Priključak

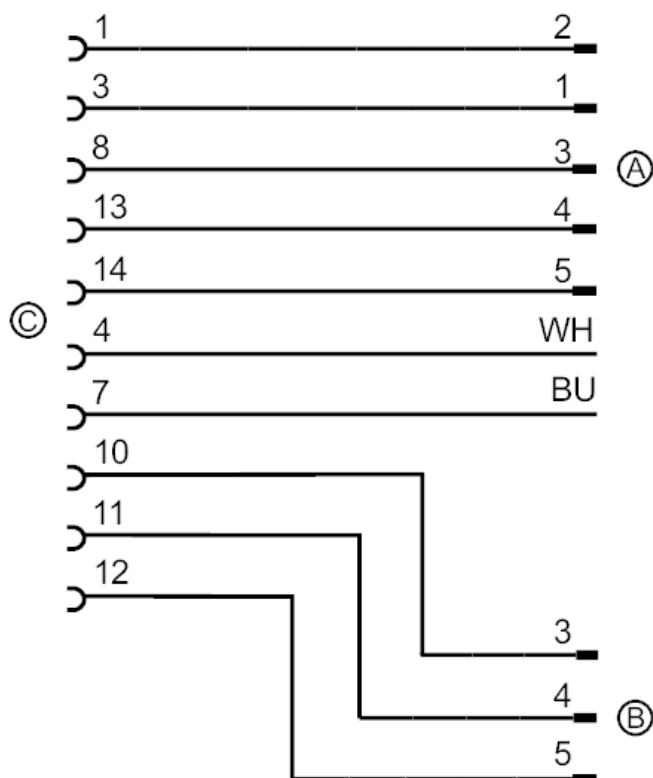

Električni priključak - A

Poveznik: 1 x M12, ravno; kodiranje: A; Zaključavanje: Mjed, niklovano; Zakretni moment pritezanja: 0,6...1,5 Nm

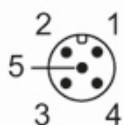

Električni priključak - B

Poveznik: 1 x M12, ravno; kodiranje: A; Zaključavanje: Mjed, niklovano; Zakretni moment pritezanja: 0,6...1,5 Nm

