


IFA2002-FRKG/V4A/6M/PH





IF5684

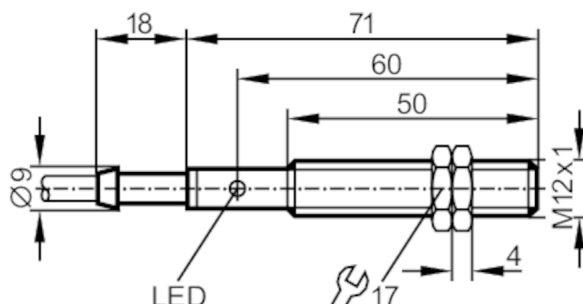

Induktivni sensor

IFA2002-FRKG/V4A/6M/PH

Radni uvjeti		
Temperatura okoline	[°C]	-25...80
Zaštita		IP 67
Testovi / odobrenja		
EMC	EN 60947-5-2	
	EN 55011	Razred B
MTTF	[godina]	1815
Mehanički podaci		
Težina	[g]	237
Kućiste		Tip navoja
Način ugradnje		izravno ugradivo
Dimenzije	[mm]	M12 x 1 / L = 71
Oznaka navoja		M12 x 1
Materijali		nehrđajući čelik (1,4571/316Ti); PBT
Prikazi / radni elementi		
Prikaz	Status prekapčanja	1 x LED, Žuto
Dodatna oprema		
Isporuka obuhvata		zaporne matice: 2
Opaske		
Količina pakiranja		1 kom.
Električni priključak		
Kabel: 6 m, PUR; 2 x 0,34 mm ²		
Priključak		

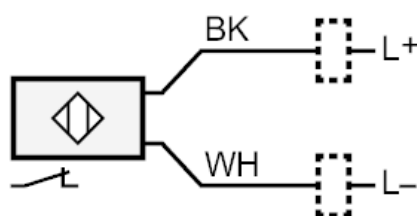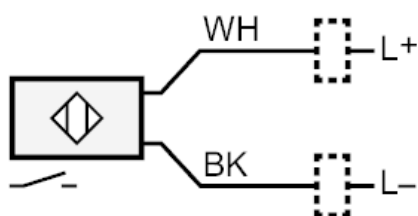

BK = Boje žica :
crno
WH = Bijelo