


IGA2008-FRKG/12M





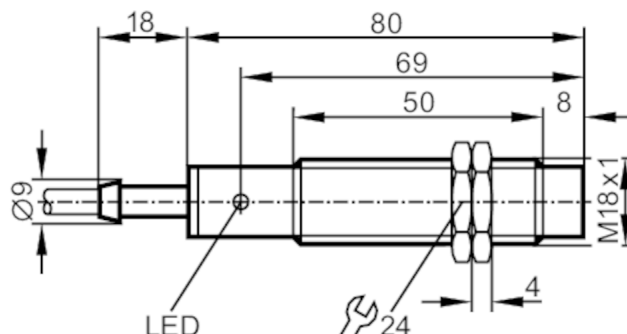

Induktivni sensor

IGA2008-FRKG/12M

Radni uvjeti		
Temperatura okoline	[°C]	-25...80
Zaštita		IP 67
Testovi / odobrenja		
EMC	EN 60947-5-2	
	EN 55011	Razred B
MTTF	[godina]	1626
Mehanički podaci		
Težina	[g]	517
Kućiste		Tip navoja
Način ugradnje		neizravno ugradivo
Dimenzije	[mm]	M18 x 1 / L = 80
Oznaka navoja		M18 x 1
Materijali		Mjed presvučeno bijelom broncom; PBT bezbojno
Prikazi / radni elementi		
Prikaz	Status prekapćanja	1 x LED, Žuto
Dodatna oprema		
Isporuka obuhvata		zaporne matice: 2
Opaske		
Količina pakiranja		1 kom.
Električni priključak		
Kabel: 12 m, PVC; 2 x 0,5 mm ²		
Priključak		

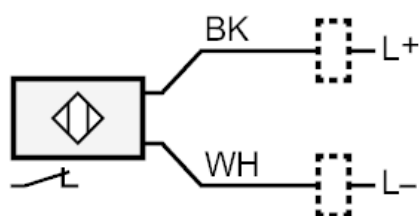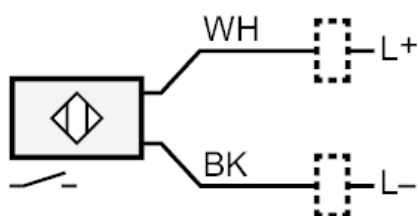

BK = Boje žica :
 WH = crno
 Bijelo