


CR1052



Programmable graphic display for controlling mobile machines

R360/PDM360/compact/MONO

Article no longer available - archive entry

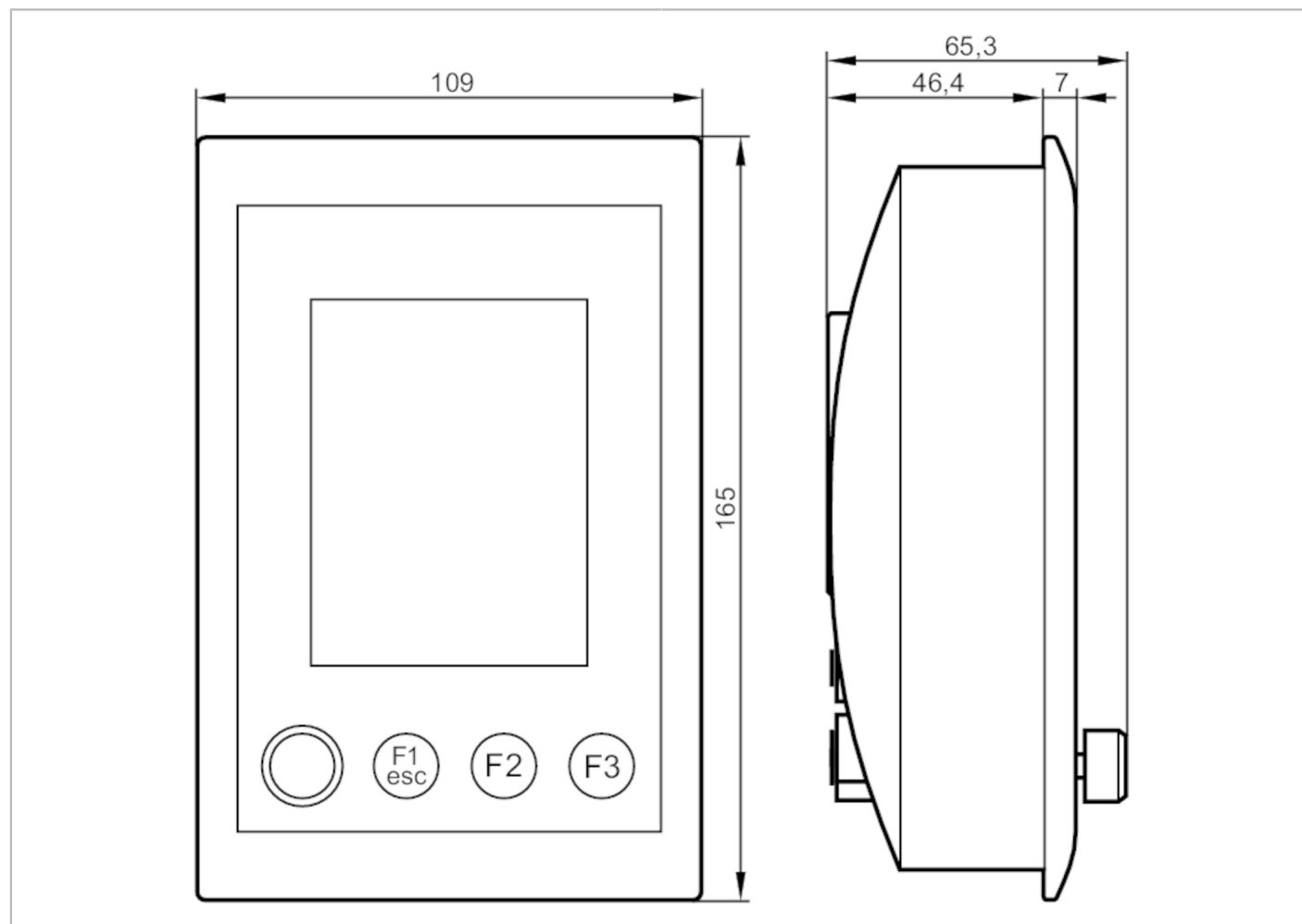

Electrical data

Operating voltage	[V]	10...32 DC
-------------------	-----	------------

Software / programming

PLC function to IEC 61131-3	yes
-----------------------------	-----

Interfaces

Number of CAN interfaces	1
Number of Ethernet interfaces	1
Number of RS232 interfaces	1

Mechanical data

Weight	[g]	1439.6
Type of mounting	panel / surface	
Dimensions	[mm]	165 x 109 x 65.3

Displays / operating elements

Display	3,8" monochrome display
---------	-------------------------

CR1052



Programmable graphic display for controlling mobile machines

R360/PDM360/compact/MONO

Operating elements	3	freely programmable backlit function keys
	1	encoder with pushbutton
Display resolution	320 x 240	
Display type	monochrome display	
Display size	3.8"	
Display background illumination	LED	

Remarks

Pack quantity	1 pcs.
---------------	--------

Electrical connection

Connector: 1 x M12