


# E11641



## Connection cable

VDOGH050VAS00,6E05STGH050VAS

Article no longer available - archive entry

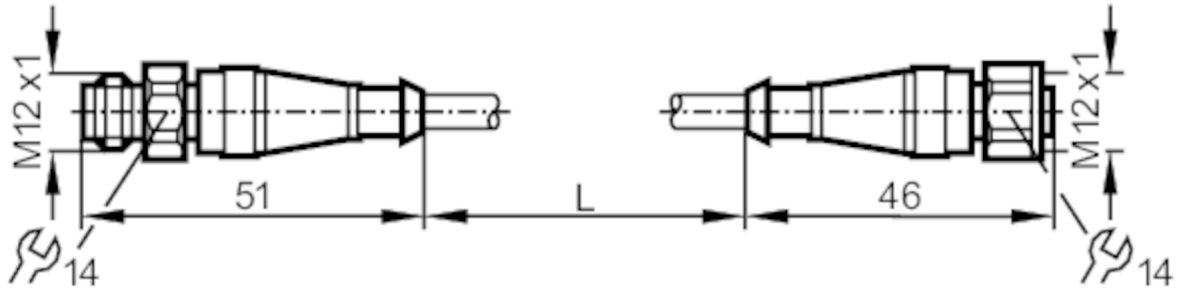

### Application

Special feature	Free from silicone; Gold-plated contacts
Free from silicone	yes

### Electrical data

Operating voltage	[V]	< 30 AC / < 36 DC
Max. current load total	[A]	4

### Operating conditions

Ambient temperature	[°C]	-25...100
Protection		IP 68; IP 69K

### Mechanical data


Materials	PVC
Material nut	stainless steel (1.4404 / 316L) / stainless steel (1.4404 / 316L)

### Remarks

Pack quantity	1 pcs.
---------------	--------

### Electrical connection - plug

Connector: 1 x M12, straight; Moulded body: PVC; Locking: stainless steel (1.4404 / 316L); Contacts: gold-plated; Tightening torque: 0.7...0.9 Nm

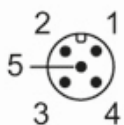

# E11641




## Connection cable

VDOGH050VAS00,6E05STGH050VAS

### Electrical connection


Cable: 0.6 m, PVC, orange, Ø 5.3 mm; 5 x 0.25 mm<sup>2</sup> (32 x Ø 0.1 mm )

### Connection

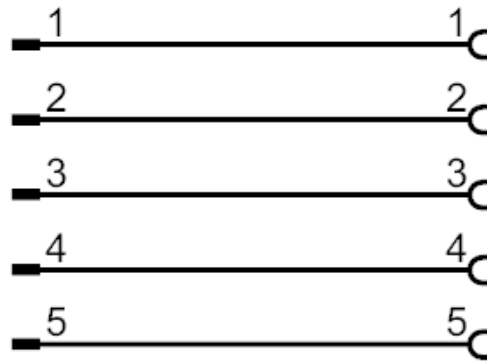

### Electrical connection - socket

Connector: 1 x M12, straight; Moulded body: PVC; Locking: stainless steel (1.4404 / 316L); Contacts: gold-plated; Tightening torque: 0.7...0.9 Nm

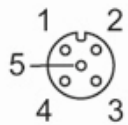

Article no longer available - archive entry