

E11720



Splitter box

ZDO6H050MSS0005H07

Mechanical data

Materials	TPU
Number of ports splitter box	6
Connector type	M12

Remarks


Pack quantity	1 pcs.
---------------	--------

Electrical connection

Cable: 5 m, PUR, Halogen-free, black, Ø 9 mm; 6 x 0.34 mm² (43 x Ø 0.1 mm) + 3 x 0.75 mm² (95 x Ø 0.1 mm)

Electrical connection - slot

Connector: 6 x M12; Moulded body: TPU; Contacts: gold-plated; Tightening torque: 0.5 Nm

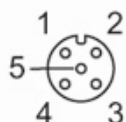

E11720



Splitter box

ZDO6H050MSS0005H07

Connection

<u>BN</u>	1 (1...6)	C
<u>BU</u>	3 (1...6)	C
<u>GN/YE</u>	5 (1...6)	C
<u>WH</u>	4 (1)	C
<u>GN</u>	4 (2)	C
<u>YE</u>	4 (3)	C
<u>GY</u>	4 (4)	C
<u>PK</u>	4 (5)	C
<u>RD</u>	4 (6)	C

Core colours :

BN =	brown
BU =	blue
GN =	green
GY =	grey
PK =	pink
RD =	red
WH =	white
YE =	yellow

Article no longer available - archive entry

replaced by: EBC017