




Connecting cable with socket

ADOGG040--S0005A03

Article no longer available - archive entry

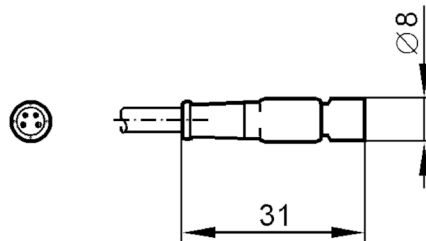

Electrical data

Operating voltage	[V]	< 60 AC / < 75 DC
Protection class		III

Operating conditions

Ambient temperature	[°C]	-25...90
Protection		IP 65

Mechanical data

Dimensions	[mm]	8 x 8 x 31
Materials		TPU

Remarks

Pack quantity		1 pcs.
---------------	--	--------

Electrical connection

Cable: 5 m, PUR / PVC, orange, Ø 5 mm; 4 x 0.25 mm² (32 x Ø 0.1 mm)

Electrical connection - socket

Connector: 1 x M8, straight; Moulded body: TPU

Connector: 1 x M8, straight; Moulded body: TPU




E11189



Connecting cable with socket

ADOGG040--S0005A03

Connection

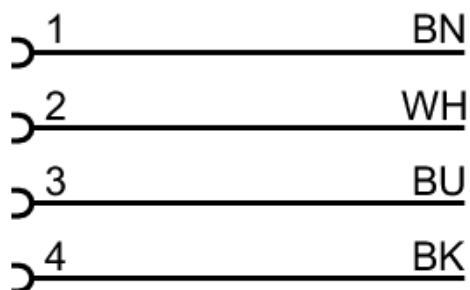

Core colours :

BK = black
BN = brown
BU = blue
WH = white

Article no longer available - archive entry