





CAN bus terminating resistor

M12 PASSTHROUGH W/RESISTOR

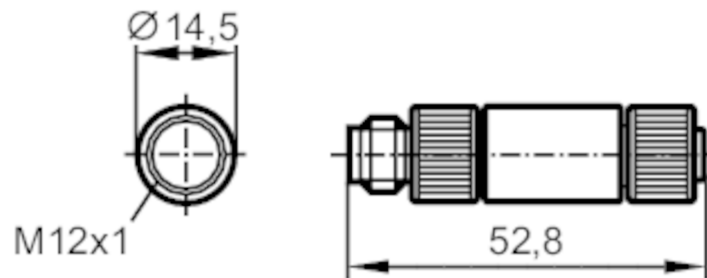

Application	
Special feature	Gold-plated contacts
Electrical data	
Operating voltage [V]	< 30 AC / < 36 DC
Max. current load total [A]	4
Operating conditions	
Ambient temperature [°C]	-40...85
Protection	IP 68
Mechanical data	
Weight [g]	22.68
Dimensions [mm]	14.5 x 14.5 x 52.8
Materials	PVC
Material nut	brass, nickel-plated / brass, nickel-plated
Remarks	
Pack quantity	1 pcs.
Electrical connection - plug	

Connector: 1 x M12, straight; Moulded body: PVC; Locking: brass, nickel-plated; Contacts: gold-plated

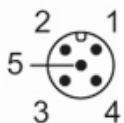

E18267




CAN bus terminating resistor

M12 PASSTHROUGH W/RESISTOR

Electrical connection - socket

Connector: 1 x M12, straight; Moulded body: PVC; Locking: brass, nickel-plated; Contacts: gold-plated

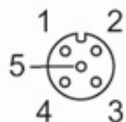

Connection

