




Fibre optic diffuse reflection sensor

FT-30-A-A-E6/1,5m

Article no longer available - archive entry

Alternative articles: E20290
When selecting an alternative article and accessories please note that technical data may differ!

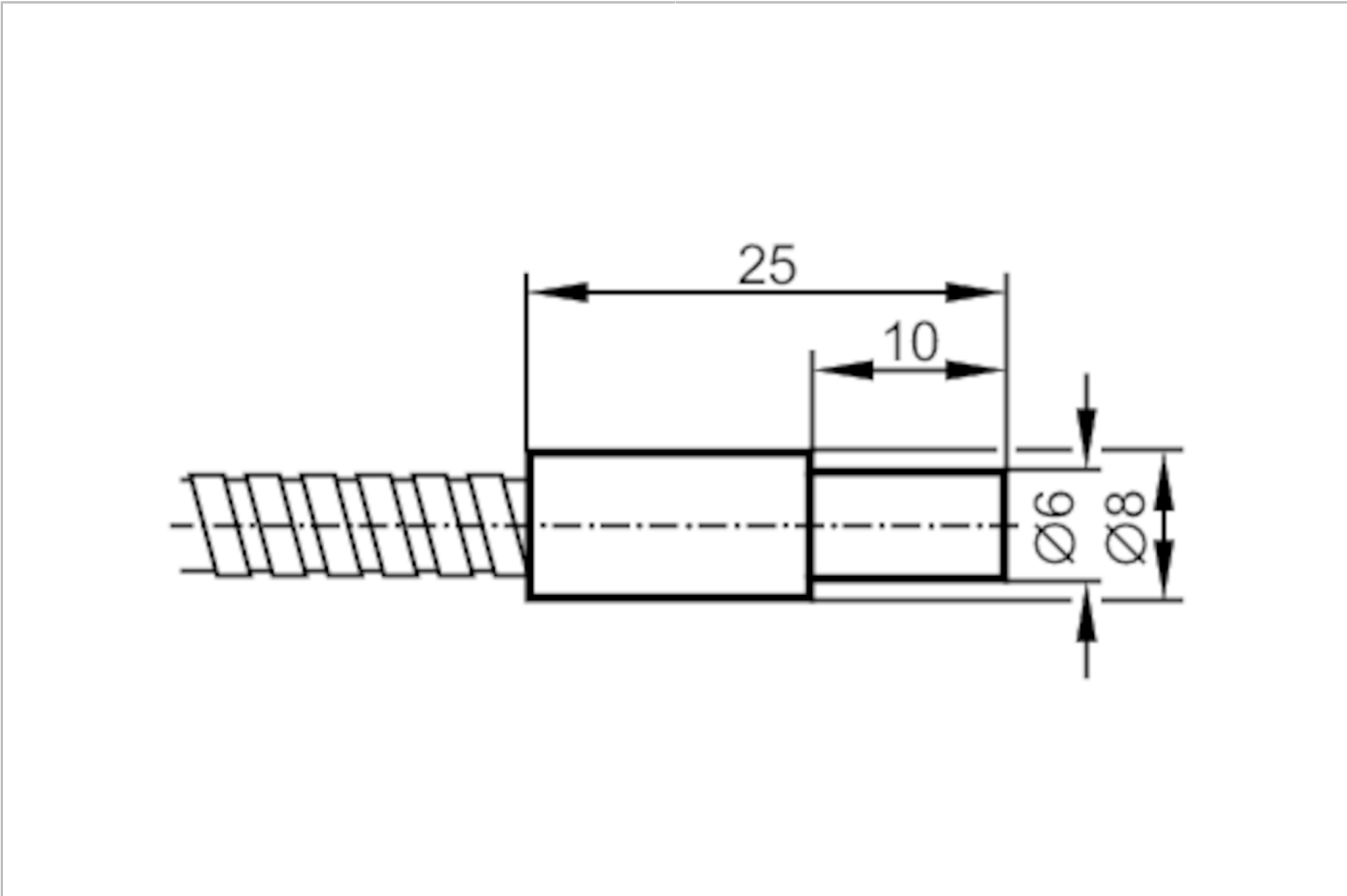

Application	
Function principle	Diffuse reflection sensor
Detection zone	
Range with fibre optic amplifier type	OIF
OIF	
Range fibre optics [mm]	36
Operating conditions	
Ambient temperature [°C]	-40...290
Mechanical data	
Version of sensing head	straight
Sensing head diameter [mm]	6
Total length [mm]	1500
Min. bending radius [mm]	30
Materials	Adapter: PA
Fibre material	glass
Fibre head material	aluminium

E20439



Fibre optic diffuse reflection sensor

FT-30-A-A-E6/1,5m

Fibre sheath material	aluminium
Remarks	
Pack quantity	1 pcs.