


Fibre optic through-beam sensor

FE-00-M-V-E3/2,5m

Article no longer available - archive entry

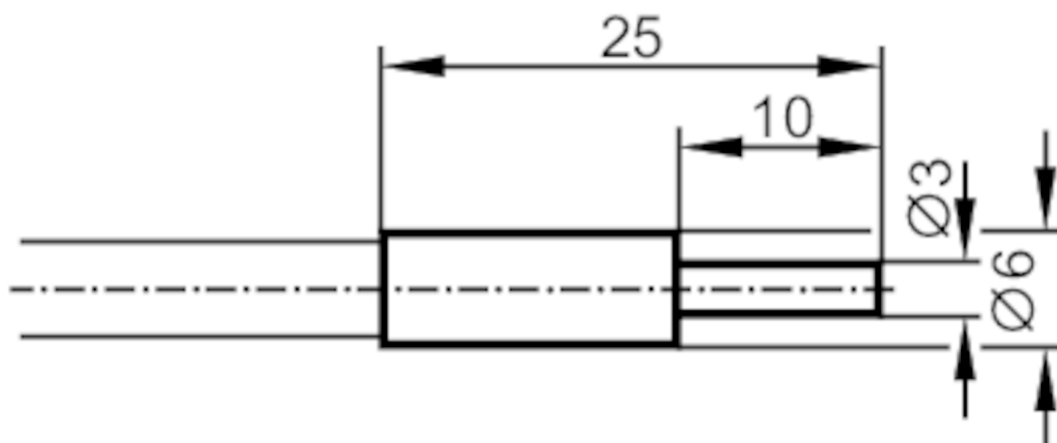

Application

Function principle

Through-beam sensor

Detection zone

Range with fibre-optic
amplifier type

OKF; OUF

OKF

Range of fibre optics

[mm]

85

OUF

Range of fibre optics

[mm]

85

Operating conditions

Ambient temperature

[°C]

-20...150

Mechanical data

Version of sensing head

straight

Sensing head diameter

[mm]

3

Sensing head length

[mm]

10

Total length

[mm]

2500

Min. bending radius

[mm]

20

Fibre material

glass

Fibre head material

stainless steel (1.4305 / 303)

E20538



Fibre optic through-beam sensor

FE-00-M-V-E3/2,5m

Fibre sheath material	metal silicone
Remarks	
Pack quantity	1 pcs.