

# E20148




## Fibre optic diffuse reflection sensor

FT-30-A-A-M8/2M

discontinued article

replaced by: E20137 – Discontinuation date: 31.03.2017

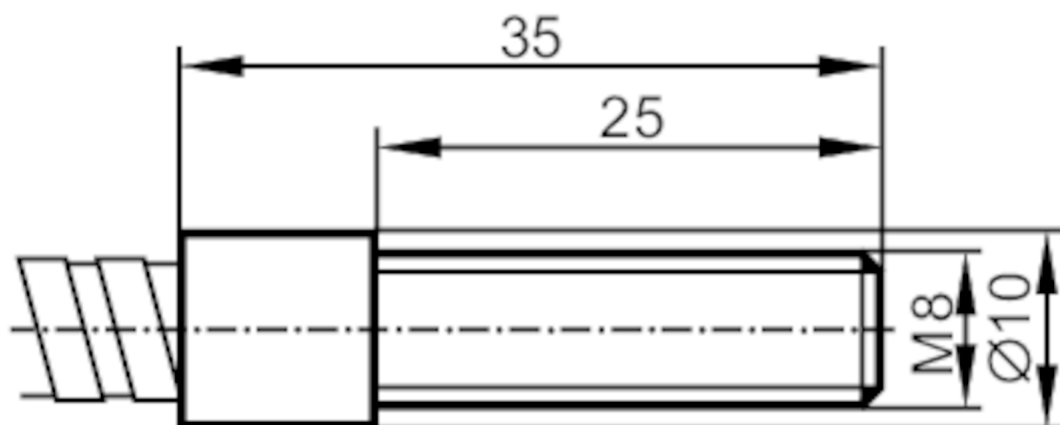

### Application

Function principle Diffuse reflection sensor

### Detection zone

Range with fibre optic amplifier type OIF

### OIF

Range fibre optics [mm] 56

### Operating conditions

Ambient temperature [°C] -40...290

# E20148



## Fibre optic diffuse reflection sensor

FT-30-A-A-M8/2M

Mechanical data	
Weight [g]	164
Version of sensing head	straight
Sensing head thread	M8
Total length [mm]	2000
Min. bending radius [mm]	30; (for fixed installation)
Fibre arrangement	⓪
Materials	Adapter: PA
Fibre material	glass
Fibre head material	aluminium
Fibre sheath material	aluminium
Accessories	
Accessories (supplied)	hexagon nuts: 2 x M8, stainless steel
	tooth lock washers: 2
	knurled nut: 1 x M30
Remarks	
Notes	discontinued article
Pack quantity	1 pcs.

discontinued article

replaced by: E20137 – Discontinuation date: 31.03.2017