


EVC09A



Connection cable

VDOAH040VAT00,3H04STAHO40VAT

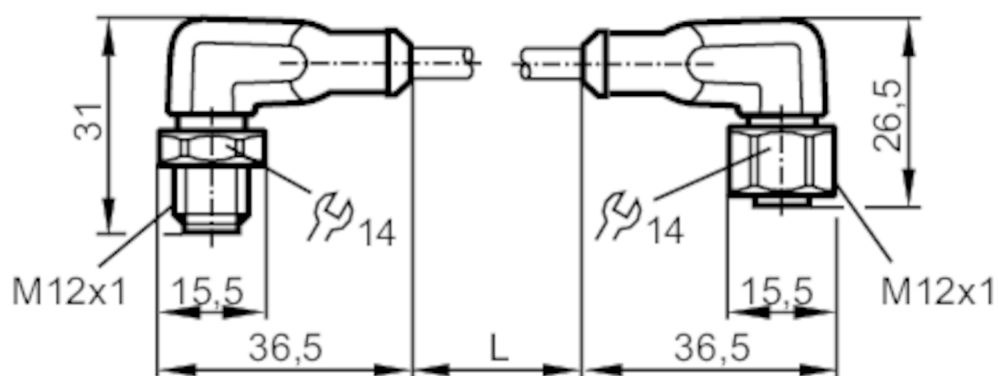

Application

Special feature	Halogen-free; Gold-plated contacts
Compatible with paint	yes

Electrical data

Operating voltage	[V]	< 60 AC/DC
Protection class		II
Max. current load total	[A]	2

Operating conditions

Ambient temperature	[°C]	-20...60
Protection		IP 67; (when used outside the hazardous area: IP 68 / IP 69K)

Tests / approvals

Approval	BVS 08 ATEX E 109 U; IECEx BVS 08.0041 U
ATEX marking	 II 3G Ex nA IIC Gc
	 II 2D Ex tb IIIC Db IP65/IP67

Mechanical data

Weight	[g]	60.8
Dimensions	[mm]	31 x 15.5 x 36.5
Materials		housing: TPU orange; Sealing: FKM
Material nut		stainless steel (316L/1.4404)

Remarks

Pack quantity	1 pcs.
---------------	--------

EVC09A



Connection cable

VDOAH040VAT00,3H04STAH040VAT

Electrical connection - plug


Connector: 1 x M12, angled; coding: A; Locking: stainless steel (316L/1.4404); Contacts: gold-plated; Tightening torque: 1.2...1.5 Nm



Electrical connection

Cable: 0.3 m, PUR, Halogen-free, black, Ø 4.9 mm; 4 x 0.34 mm² (42 x Ø 0.1 mm)

Connection

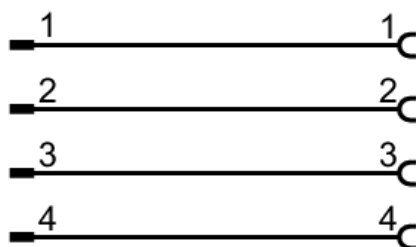

Electrical connection - socket

Connector: 1 x M12, angled; coding: A; Locking: stainless steel (316L/1.4404); Contacts: gold-plated; Tightening torque: 1.2...1.5 Nm

