




Modul diagnosis AS-Interface

AS-i Tuner IP67

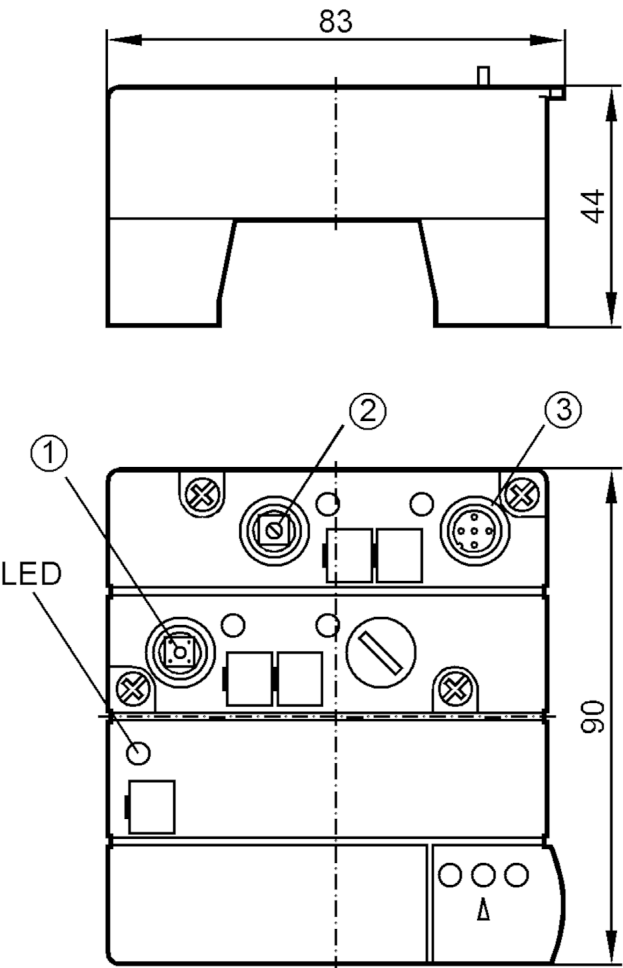

- 1 tombol tune
- 2 rotary switch
- 3 Soket distribusi AS-i M12




Aplikasi		
Aplikasi		alat diagnostik untuk AS-i
Data kelistrikan		
Tegangan nominal DC	[V]	26.5...31.6
Konsumsi arus maks. dari AS-i	[mA]	60
Pelindung polaritas terbalik		ya
Pemantauan tegangan rendah		ya
Kondisi pengoperasian		
Suhu sekitar	[°C]	0...55
Perlindungan		IP 67
Pengujian/persetujuan		
MTTF	[ANN]	140



Modul diagnosis AS-Interface

AS-i Tuner IP67

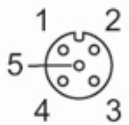Data teknis		
Berat	[g]	199.2
Material		PBT
Elemen display/pengoperasian		
Display	operasi	LED, hijau
	peringatan	LED, kuning
	kesalahan	LED, merah
Aksesori		
Aksesori (opsional)		Bagian bawah modul:, AC5000
Keterangan		
Keterangan		tidak diperlukan pengalamatan
		peringkat arus soket distribusi AS-i maks. 1 A
Jumlah paket		1 buah
Koneksi listrik		
pin kontak pada bagian bawah modul, FK:		
Konektor: M12; pengkodean: A		
		
1	Soket distribusi AS-i M12	
3	AS-i +	
	AS-i -	