


AC1304



PLC AS-Interface

ControllerE 2Mstr 1RS232C

Produk tidak tersedia - entri arsip

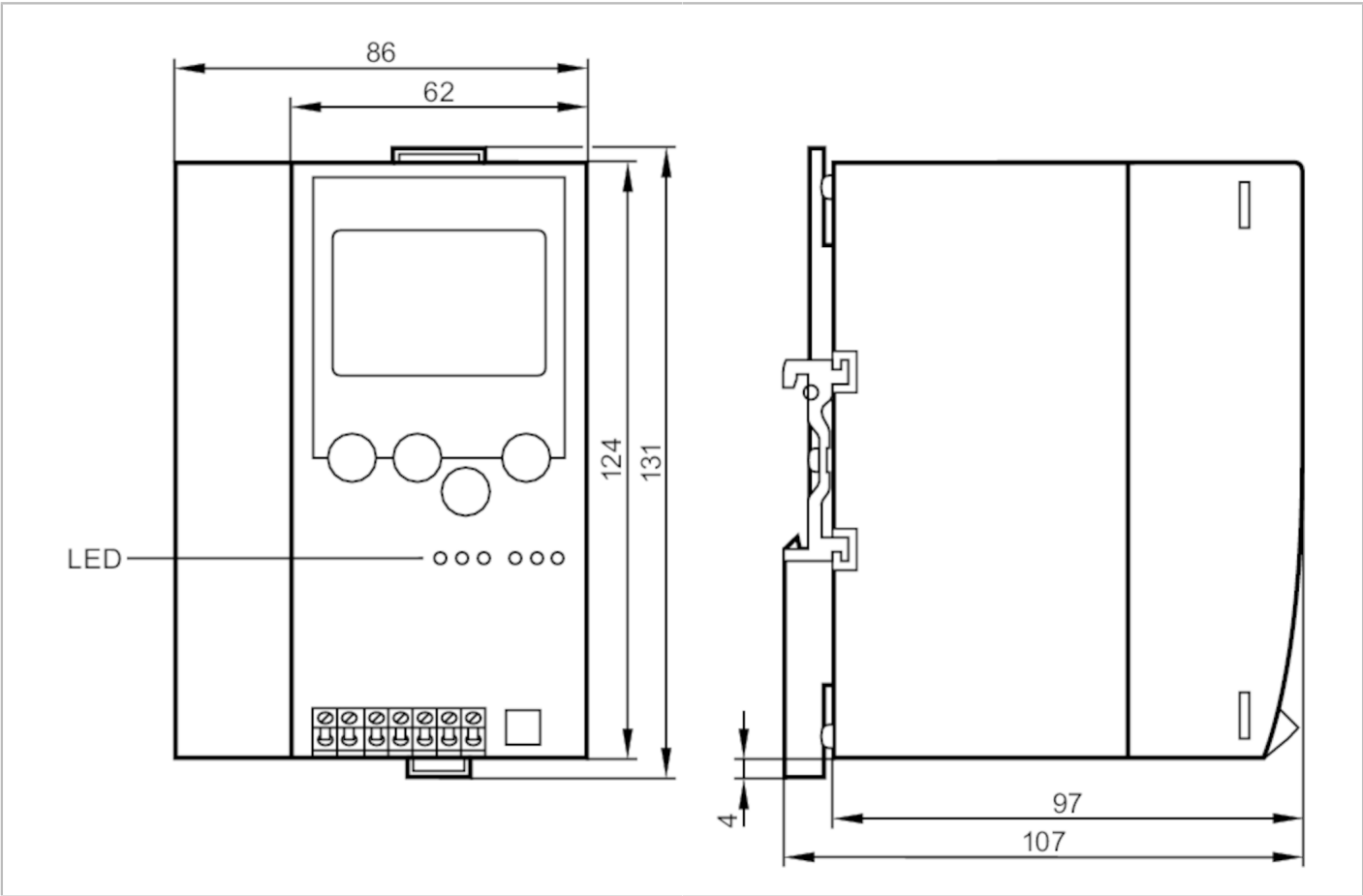

Aplikasi		
Aplikasi	pengontrol terdesentralisasi	
Data kelistrikan		
Tegangan pengoperasian	[V]	24 DC; ("kelas suplai 2" menurut cULus)
Peringkat isolasi	[V]	500
Konsumsi arus	[mA]	< 500
Konsumsi arus maks. dari AS-i	[mA]	10
Konsumsi daya maks.	[VA]	10
Jumlah master AS-i		2
Pemisahan potensial		ya
Interface		
Interface komunikasi	RS232	
RS232		
Jumlah interface R232	1	
Laju transmisi	9600...115200 Baud	
Tipe konektor	RJ11	



PLC AS-Interface

ControllerE 2Mstr 1RS232C

Tipe penggunaan	pemrograman
Catatan tentang interface	diisolasi secara elektrik

Kondisi pengoperasian

Suhu sekitar	[°C]	0...60
Suhu penyimpanan	[°C]	-20...70
Kelembapan udara relatif maks.	[%]	95
Perlindungan		IP 20

Klasifikasi AS-i

Versi AS-i	2.1
Profil master AS-i	M3
Sertifikat AS-i	61102

Data teknis

Berat	[g]	517.4
Casing		casing untuk pemasangan rel DIN
Dimensi	[mm]	86 x 131 x 107
Material		aluminium; pelat baja galvanis

Elemen display/pengoperasian

Display	fungsi	2 x LED, merah
		3 x LED, hijau
		3 x LED, kuning
		display LCD grafis penuh

Keterangan

Jumlah paket	1 buah
--------------	--------

Koneksi listrik

Koneksi

