




Modul kabinet kontrol AS-Interface

CabinetModule 4DO R C

Produk tidak tersedia - entri arsip

Produk alternatif: AC2258

Ketika memilih produk dan aksesoris alternatif, perhatikan bahwa data teknis mungkin berbeda!

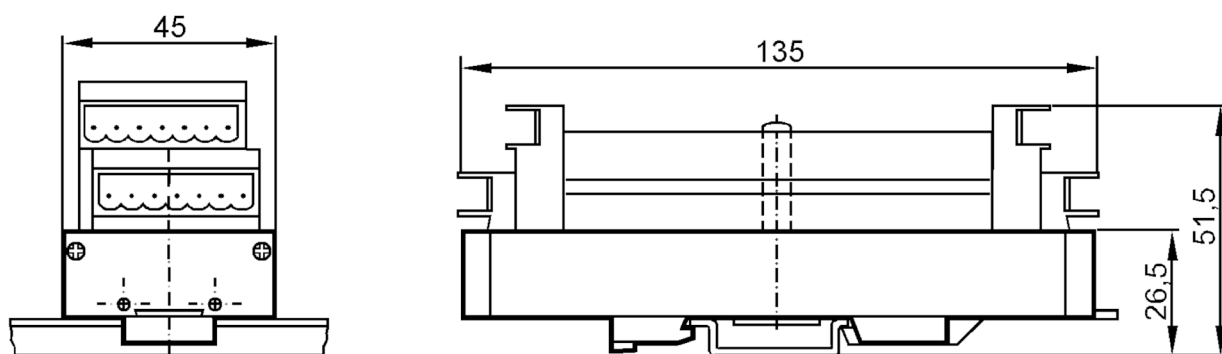

Data kelistrikan

Tegangan pengoperasian [V]	26.5...31.6 DC
Konsumsi arus [mA]	< 60
Total beban arus maks. [A]	6

Input/output

Jumlah input dan output	Jumlah output relai: 4
-------------------------	------------------------

Output

Desain kelistrikan	AS-i
Rentang tegangan DC [V]	24
Rentang tegangan AC [V]	240
Beban arus maks. per output [mA]	2500
Jumlah output relai	4
Terpisah secara elektrik	ya

Kondisi pengoperasian

Suhu sekitar [°C]	-25...50
Perlindungan	IP 20

Pengujian/persetujuan


EME	EN 50295	
	EN 50178	



Modul kabinet kontrol AS-Interface

CabinetModule 4DO R C

Klasifikasi AS-i		
Profil AS-i		S-8.0
Konfigurasi I/O AS-i	[hex]	8
Kode ID AS-i	[hex]	0
Data teknis		
Tipe pemasangan		pemasangan pada rel DIN dan panel; pemasangan tali dimungkinkan
Dimensi	[mm]	45 x 135 x 51.5
Material		PA; PVC
Elemen display/pengoperasian		
Display	status peralihan	LED, kuning
	operasi	LED, hijau
Aksesori		
Aksesori (opsional)		Konektor COMBICON:, E70198
Keterangan		
Jumlah paket		1 buah
Koneksi listrik		
COMBICON:		
Koneksi		

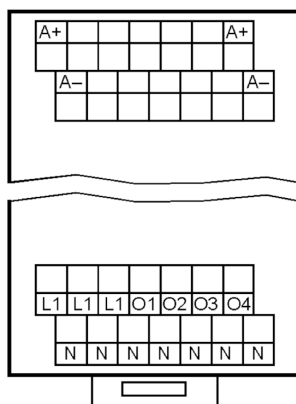

A+	AS-i +
A-	AS-i -
L1	suplai eksternal + (DC) / L1 (AC)
N	suplai eksternal - (DC) / N (AC)
O1...O4	output peralihan aktuator 1...4