


AC2900



Modul AS-Interface ProcessLine

ProcessLine 8 SB IP69K

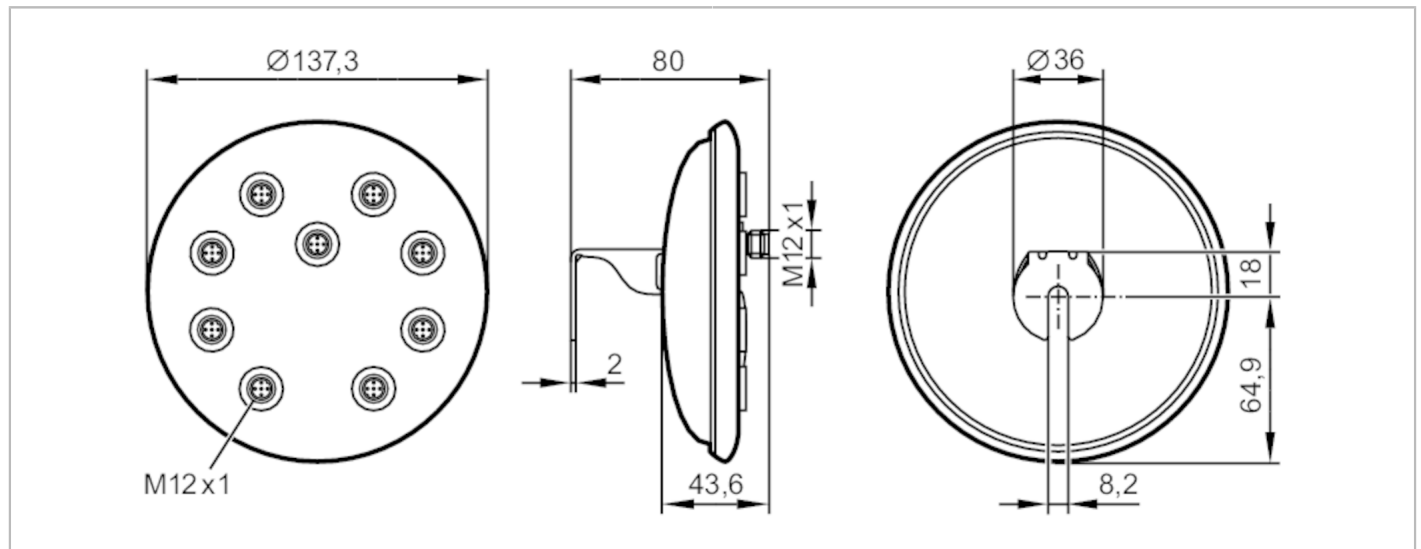

Aplikasi		
Aplikasi	area higienis dan basah pada industri makanan	
Data kelistrikan		
Tegangan pengoperasian	[V]	26.5...31.6 DC
Beban arus maks. per modul/ slot	[A]	4; (AS-i: 4 A; AUX: 4 A)
Suplai tegangan tambahan	[V]	20...30 DC; (AUX)
Kondisi pengoperasian		
Suhu sekitar	[°C]	-5...70
Suhu penyimpanan	[°C]	-5...70
Kelembapan udara relatif maks.	[%]	90; (non kondensasi)
Ketinggian maks. di atas permukaan laut	[m]	2000
Perlindungan	IP 68; IP 69K	
Tingkat kekotoran	2	
Pengujian/persetujuan		
EME	EN 62026-2	
	EN 61000-6-2	
Data teknis		
Berat	[g]	613.5
Dimensi	[mm]	Ø 137.3 / L = 80
Material	casing: baja tahan karat; O-ring: EPDM; Tutup pelindung: PP	
Material penyegel	EPDM	
Koneksi listrik		
Koneksi modul	M12	
Aksesori		
Item dikirim	Tutup pelindung: 8 x M12, E70297	
Aksesori (opsional)	Kunci torsi: E70390	



Modul AS-Interface ProcessLine

ProcessLine 8 SB IP69K


Keterangan

Jumlah paket

1 buah

Koneksi listrik - colokan


Konektor: 1 x M12; pengkodean: A; Segel: EPDM; Torsi pengencangan: 1.2...1.4 Nm; Panjang kabel maksimal: 2 m

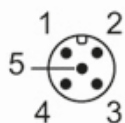

1	AS-i+
2	0 V
3	AS-i -
4	+24 V
5	FE

Koneksi listrik - soket

Konektor: 8 x M12; pengkodean: A; Segel: EPDM; Torsi pengencangan: 1.2...1.4 Nm; Panjang kabel maksimal: 20 m

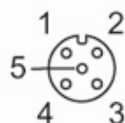

1	AS-i+
2	0 V
3	AS-i -
4	+24 V
5	FE