


Sensor ganda AS-Interface untuk aktuatur katup pneumatik

DUAL SENSOR T4 2SI M12

Produk tidak tersedia - entri arsip

Produk alternatif: AC2315

Ketika memilih produk dan aksesoris alternatif, perhatikan bahwa data teknis mungkin berbeda!

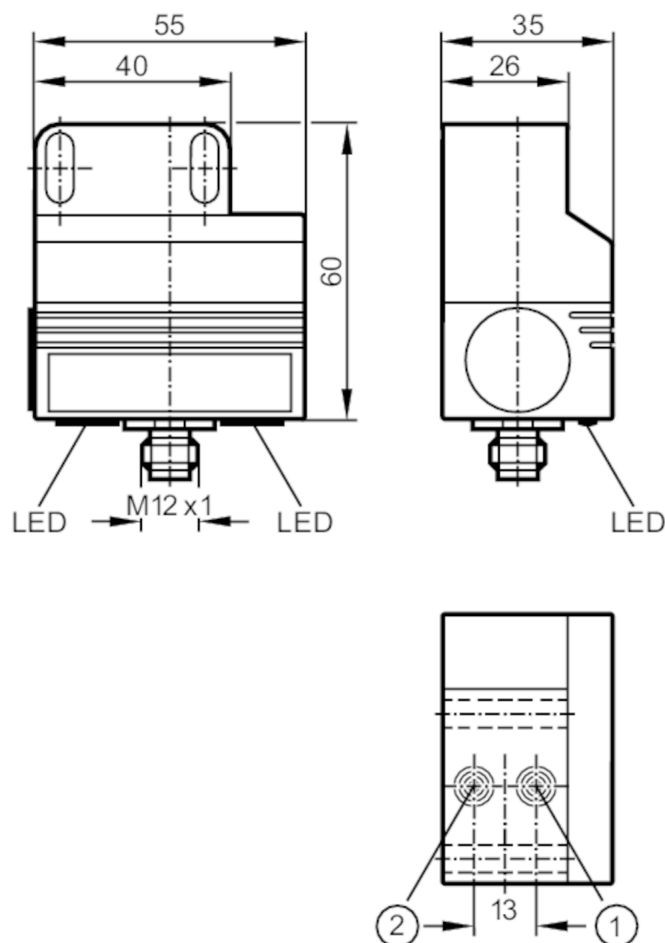

1 sensor 1
2 sensor 2



Karakteristik produk

Jangkauan pendeteksian	[mm]	4
Dimensi	[mm]	55 x 60 x 35

Data kelistrikan

Tegangan pengoperasian	[V]	26.5...31.6 DC
------------------------	-----	----------------

Zona pendeteksian

Jangkauan pendeteksian	[mm]	4
------------------------	------	---

Kondisi pengoperasian

Suhu sekitar	[°C]	-20...70
Perlindungan		IP 67

Klasifikasi AS-i

Konfigurasi I/O AS-i	[hex]	7
----------------------	-------	---



Sensor ganda AS-Interface untuk aktuatur katup pneumatik

DUAL SENSOR T4 2SI M12

Kode ID AS-i	[hex]	F
Sertifikat AS-i		15102

Data teknis

Pemasangan	non-flush mountable
Dimensi	[mm] 55 x 60 x 35
Material	PBT

Elemen display/pengoperasian


Display	status peralihan	2 x LED, kuning
---------	------------------	-----------------

Keterangan

Jumlah paket	1 buah
--------------	--------

Koneksi listrik - colokan

Konektor: 1 x M12; pengkodean: A; Penguncian: baja tahan karat (1.4305/303)

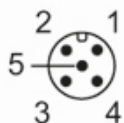

Koneksi

