


## Sensor ganda AS-Interface untuk aktuatur katup pneumatik

DUAL SENSOR T6 2SI 2DO T M12

Produk tidak tersedia - entri arsip

Produk alternatif: AC2317

Ketika memilih produk dan aksesoris alternatif, perhatikan bahwa data teknis mungkin berbeda!

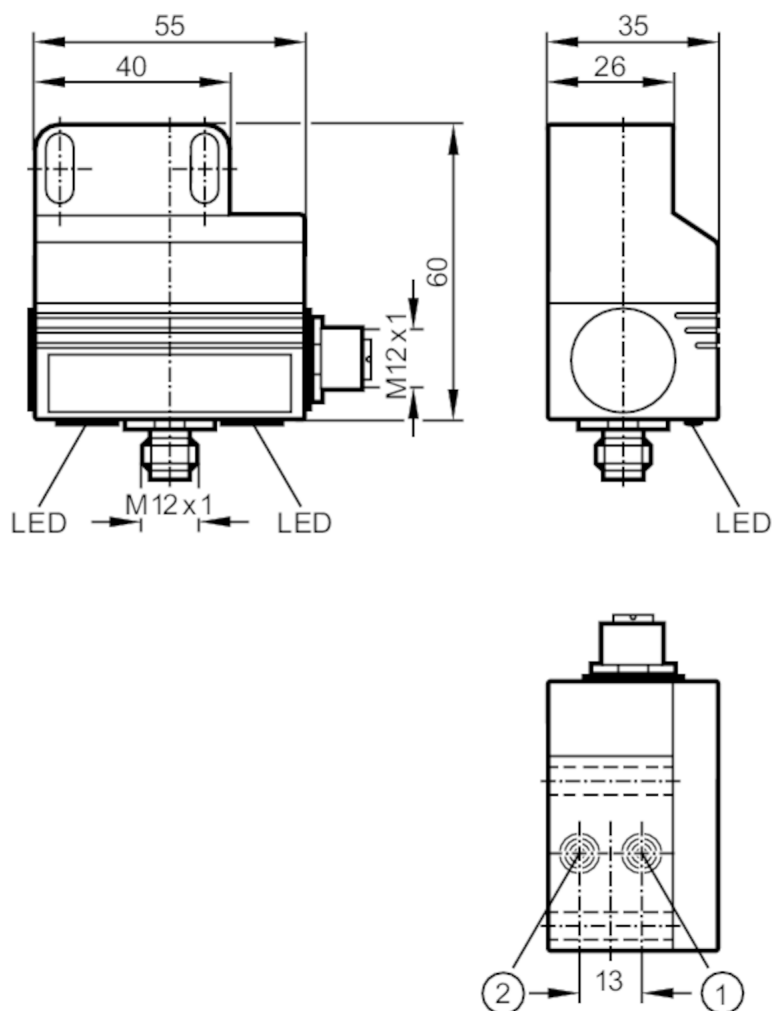

1 sensor 1  
2 sensor 2



### Karakteristik produk

|                        |      |              |
|------------------------|------|--------------|
| Jangkauan pendeteksian | [mm] | 4            |
| Dimensi                | [mm] | 55 x 60 x 35 |

### Data kelistrikan

|                        |     |                |
|------------------------|-----|----------------|
| Tegangan pengoperasian | [V] | 26.5...31.6 DC |
|------------------------|-----|----------------|

### Zona pendeteksian

|                        |      |   |
|------------------------|------|---|
| Jangkauan pendeteksian | [mm] | 4 |
|------------------------|------|---|

### Kondisi pengoperasian

|              |      |          |
|--------------|------|----------|
| Suhu sekitar | [°C] | -20...70 |
| Perlindungan |      | IP 67    |



## Sensor ganda AS-Interface untuk aktuatur katup pneumatik

DUAL SENSOR T6 2SI 2DO T M12

| Pengujian/persetujuan |              |  |
|-----------------------|--------------|--|
| EME                   | EN 50081-1   |  |
|                       | EN 61000-6-2 |  |

| Klasifikasi AS-i     |       |       |
|----------------------|-------|-------|
| Konfigurasi I/O AS-i | [hex] | 7     |
| Kode ID AS-i         | [hex] | F     |
| Sertifikat AS-i      |       | 15101 |

| Data teknis |      |                     |
|-------------|------|---------------------|
| Pemasangan  |      | non-flush mountable |
| Dimensi     | [mm] | 55 x 60 x 35        |
| Material    |      | PBT; PC             |

| Elemen display/pengoperasian |         |                |
|------------------------------|---------|----------------|
| Display                      | operasi | 1 x LED, hijau |
|                              | fungsi  | 1 x LED, merah |

| Keterangan   |  |        |
|--------------|--|--------|
| Jumlah paket |  | 1 buah |

### Koneksi listrik - colokan


Konektor: 1 x M12; pengkodean: A; Bodi cetakan: baja tahan karat



| Elektrischer Anschluss |       |  |
|------------------------|-------|--|
| 1                      | AS-i+ |  |
| 3                      | AS-i- |  |

### Koneksi listrik - soket

Konektor: 1 x M12; pengkodean: A; Bodi cetakan: baja tahan karat

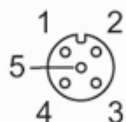

### Koneksi

| Ausgänge |                      |  |
|----------|----------------------|--|
| 2        | output peralihan 2 + |  |
| 3        | tegangan eksternal - |  |
| 4        | output peralihan 1 + |  |