


AC2315



Sensor ganda AS-Interface untuk aktuatur katup pneumatik

DUAL SENSOR T4 2SI M12

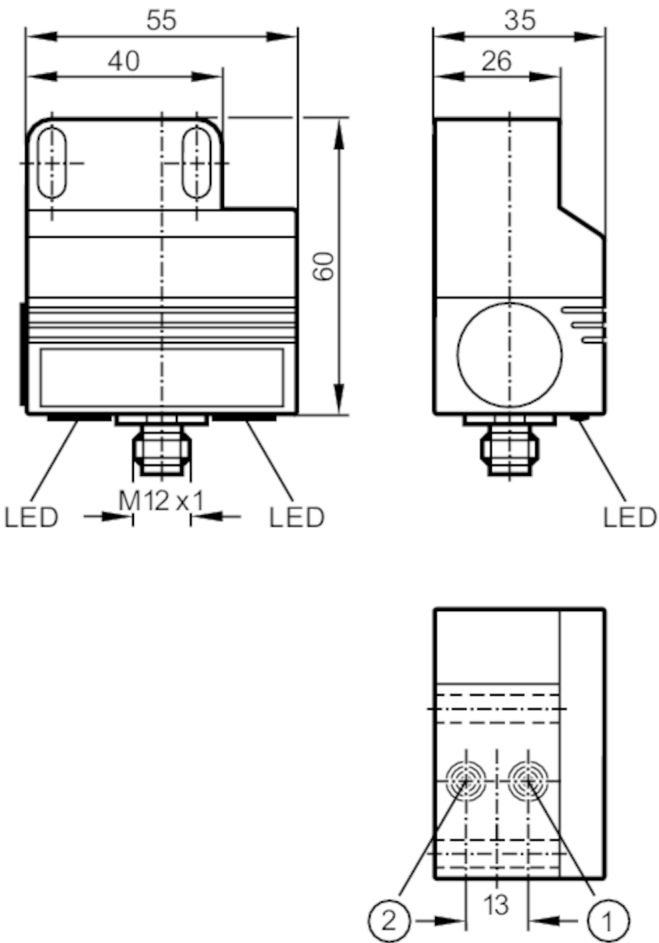

- 1 sensor 1
- 2 sensor 2



Karakteristik produk		
Desain kelistrikan		AS-i
Jangkauan pendeteksian	[mm]	4
Dimensi	[mm]	55 x 60 x 35
Data kelistrikan		
Tegangan pengoperasian	[V]	26.5...31.6 DC; ("kelas suplai 2" menurut cULus)
Konsumsi arus	[mA]	< 40
Output		
Desain kelistrikan		AS-i
Zona pendeteksian		
Jangkauan pendeteksian	[mm]	4
Kondisi pengoperasian		
Suhu sekitar	[°C]	-20...70
Perlindungan		IP 67



Sensor ganda AS-Interface untuk aktuatur katup pneumatik

DUAL SENSOR T4 2SI M12

Pengujian/persetujuan		
EME	EN 50295	
	EN 61000-6-2	
MTTF	[ANN]	924

Klasifikasi AS-i		
Versi AS-i		2.1
Mode pengalaman yang lebih luas		ya
Konfigurasi I/O AS-i	[hex]	0
Kode ID AS-i	[hex]	A.F
Sertifikat AS-i		74901

Data teknis		
Berat	[g]	149.5
Pemasangan		non-flush mountable
Dimensi	[mm]	55 x 60 x 35
Material		PBT

Elemen display/pengoperasian		
Display	status peralihan	2 x LED, kuning

Aksesori		
Item dikirim		Braket penguat
		sekrup kepala soket: 2 x M5 x 35
		washer: 2

Keterangan		
Jumlah paket		1 buah

Koneksi listrik		
-----------------	--	--

Koneksi listrik - colokan		
---------------------------	--	--

Konektor: 1 x M12; pengkodean: A; Penguncian: baja tahan karat (1.4305/303)





Sensor ganda AS-Interface untuk aktuatur katup pneumatik

DUAL SENSOR T4 2SI M12

Koneksi



Koneksi listrik

1	AS-i +
3	AS-i -