




Sensor ganda AS-Interface untuk aktuatur katup pneumatik

DUAL SENSOR T5 2SI 1DO T M12

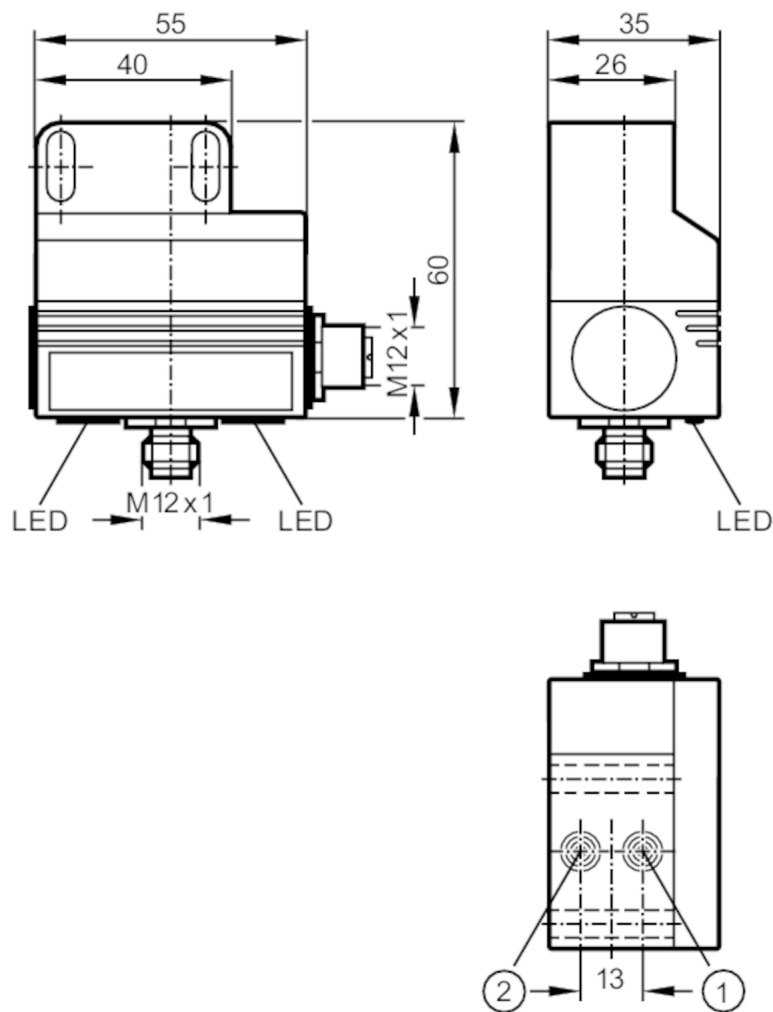

- 1 sensor 1
- 2 sensor 2



Karakteristik produk		
Desain kelistrikan		AS-i
Jangkauan pendeteksian [mm]		4
Dimensi [mm]		55 x 60 x 35
Data kelistrikan		
Tegangan pengoperasian [V]		26.5...31.6 DC; ("kelas suplai 2" menurut cULus)
Konsumsi arus [mA]		< 160
Output		
Desain kelistrikan		AS-i
Peringkat arus permanen dari output peralihan DC [mA]		100
Zona pendeteksian		
Jangkauan pendeteksian [mm]		4



Sensor ganda AS-Interface untuk aktuatur katup pneumatik

DUAL SENSOR T5 2SI 1DO T M12

Kondisi pengoperasian		
Suhu sekitar	[°C]	-20...70
Perlindungan		IP 67
Pengujian/persetujuan		
EME	EN 50295	
	EN 61000-6-2	
MTTF	[ANN]	310
Klasifikasi AS-i		
Versi AS-i		2.1
Mode pengalaman yang lebih luas		ya
Konfigurasi I/O AS-i	[hex]	7
Kode ID AS-i	[hex]	A.E
Sertifikat AS-i		75002
Data teknis		
Berat	[g]	179
Pemasangan		non-flush mountable
Dimensi	[mm]	55 x 60 x 35
Material		PBT
Elemen display/pengoperasian		
Display	status peralihan	2 x LED, kuning
Aksesori		
Item dikirim	Braket penguat	
	sekrup kepala soket: 2 x M5 x 35	
	washer: 2	
Keterangan		
Jumlah paket		1 buah
Koneksi listrik		
Koneksi listrik - colokan		

Konektor: 1 x M12; pengkodean: A; Penguncian: baja tahan karat (1.4305/303)






Sensor ganda AS-Interface untuk aktuatur katup pneumatik

DUAL SENSOR T5 2SI 1DO T M12

Koneksi

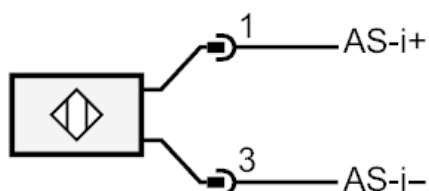


Koneksi listrik

1	AS-i +
3	AS-i -

Koneksi listrik - soket

Konektor: 1 x M12; pengkodean: A; Penguncian: baja tahan karat (1.4305/303)

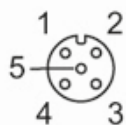

Output

3	tegangan eksternal -
4	output peralihan 1 +