


AC327A



Sensor ganda AS-Interface untuk aktuatur katup pneumatik

DUAL SENSOR T6 2SI 2DO T 3D

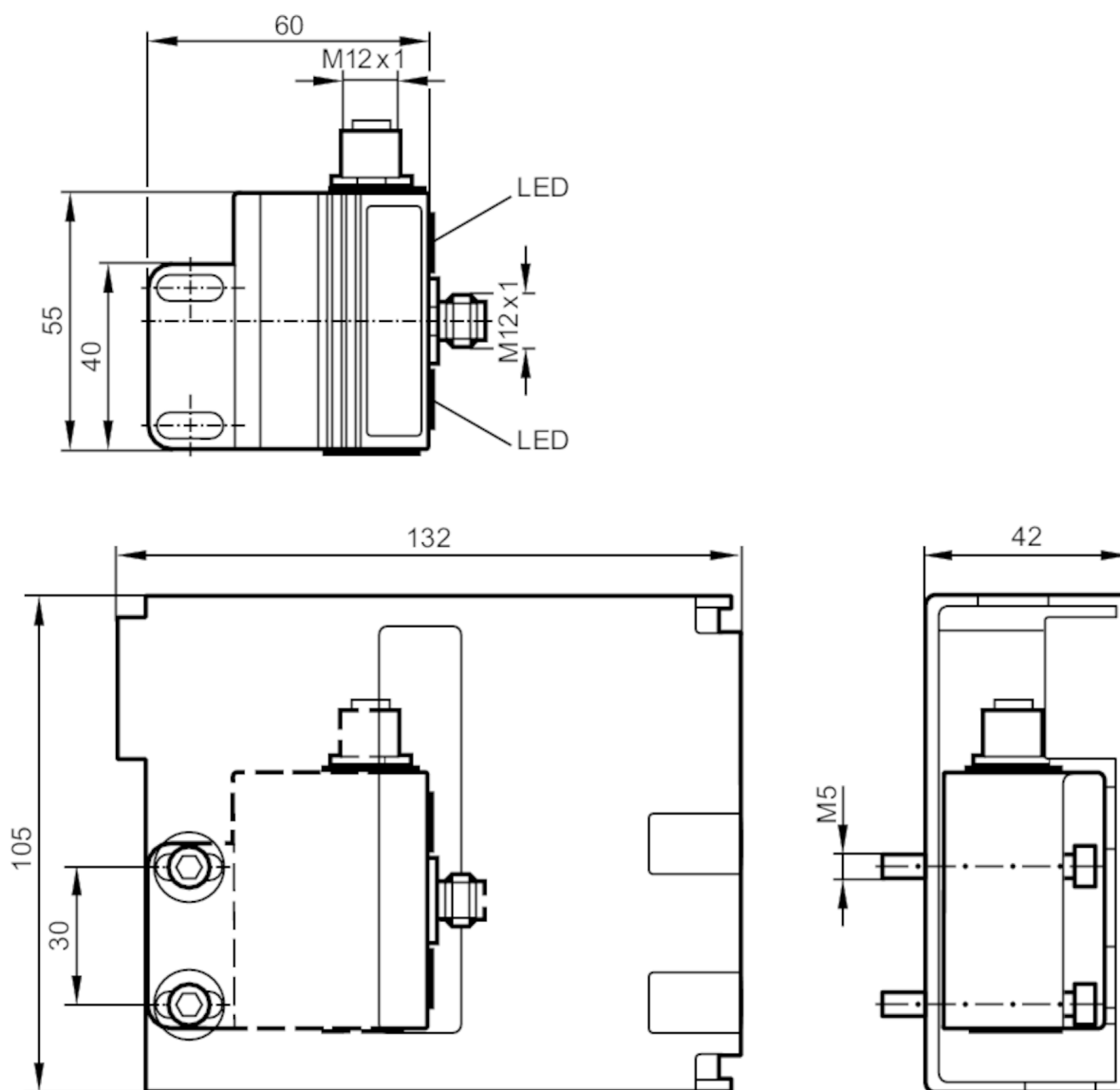

Karakteristik produk

Jangkauan pendeteksian	[mm]	4
Dimensi	[mm]	55 x 60 x 35

Data kelistrikan

Tegangan pengoperasian	[V]	26.5...31.6 DC
Konsumsi arus	[mA]	< 260
Kelas perlindungan		III

Zona pendeteksian

Jangkauan pendeteksian	[mm]	4
------------------------	------	---



Sensor ganda AS-Interface untuk aktuatur katup pneumatik

DUAL SENSOR T6 2SI 2DO T 3D

Keping target jarak pengoperasian	[mm]	74
-----------------------------------	------	----

Kondisi pengoperasian

Suhu sekitar	[°C]	-10...50
Perlindungan		IP 5x; (jika digunakan di luar area berbahaya: IP 67)

Pengujian/persetujuan

Tanda ATEX		II 3D Ex tc IIIB T85°Dc IP5X X
Catatan tentang tanda ATEX		hanya bersama dengan casing perlindungan benturan
EME	EN 50295	

Klasifikasi AS-i

Versi AS-i		2.1
Mode pengalaman yang lebih luas		ya
Konfigurasi I/O AS-i	[hex]	7
Kode ID AS-i	[hex]	A.E

Data teknis

Berat	[g]	783.5
Dimensi	[mm]	55 x 60 x 35
Material		casing: PBT oranye; penutup: PC hitam; Casing perlindungan benturan: baja tahan karat

Elemen display/pengoperasian

Display	operasi	1 x LED, hijau
	fungsi	1 x LED, kuning

Aksesori

Item dikirim		Casing perlindungan benturan
		Pelat pemasangan: 1
		sekrup kepala soket: 2 x M5 x 35

Keterangan

Keterangan		Output tidak boleh diatur secara bersamaan jika arus beban total melebihi 100 mA.
Jumlah paket		1 buah

Koneksi listrik - colokan

Konektor: 1 x M12; pengkodean: A; Bodi cetakan: baja tahan karat



Elektrischer Anschluss

1	AS-i+
3	AS-i -




Sensor ganda AS-Interface untuk aktuatur katup pneumatik

DUAL SENSOR T6 2SI 2DO T 3D

Koneksi listrik - soket

Konektor: 1 x M12; pengkodean: A; Bodi cetakan: baja tahan karat

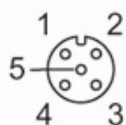

Koneksi

Ausgänge

2	output peralihan 2 +
3	tegangan eksternal -
4	output peralihan 1 +
1, 5	nicht belegt