


AC326A



Sensor ganda AS-Interface untuk aktuatur katup pneumatik

DUAL SENSOR T5 2SI 1DO T/3G

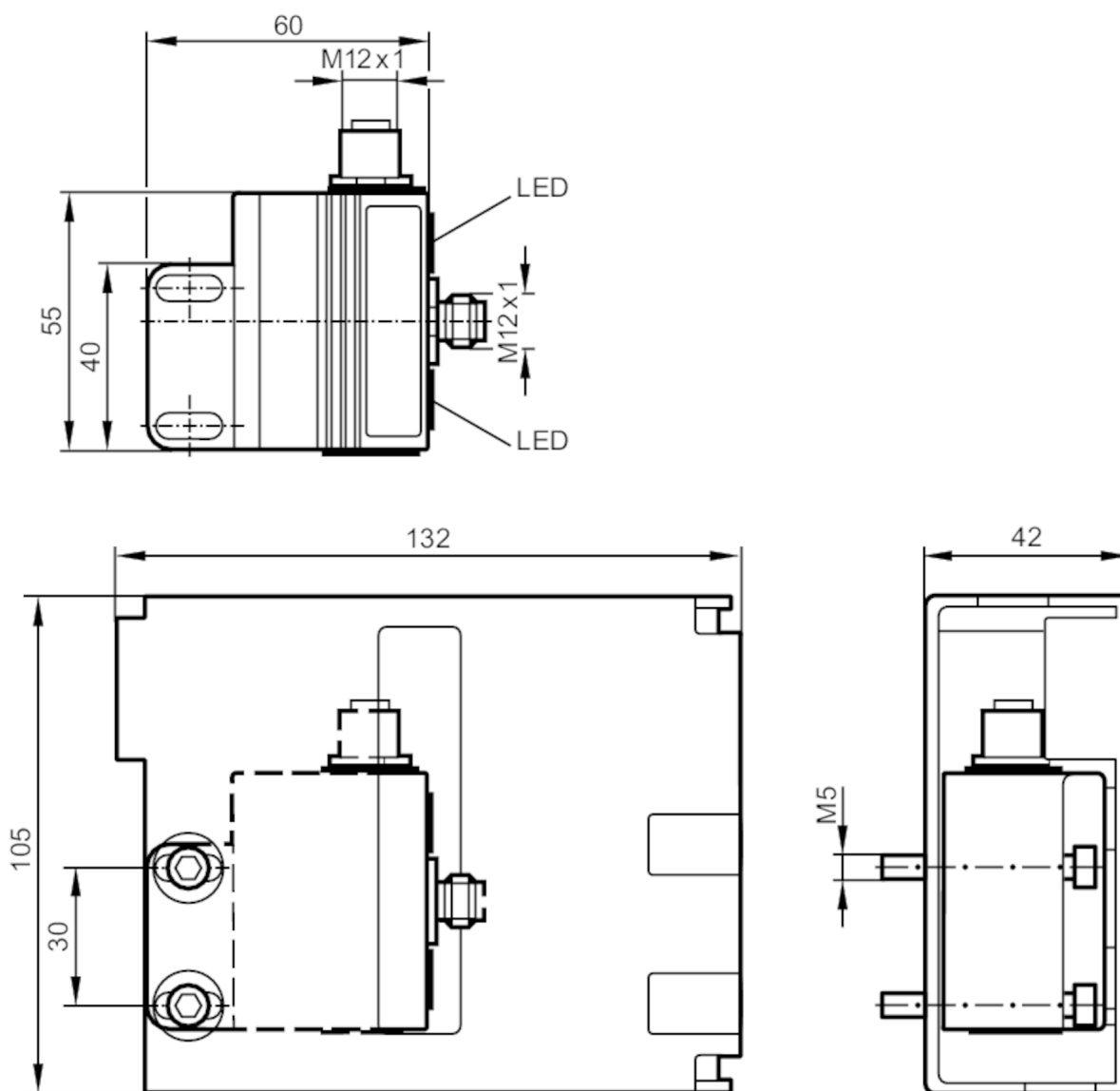

Karakteristik produk

Jangkauan pendeteksian	[mm]	4
Dimensi	[mm]	55 x 60 x 35

Data kelistrikan

Tegangan pengoperasian	[V]	26.5...31.6 DC
Konsumsi arus	[mA]	< 160
Kelas perlindungan		III

Zona pendeteksian

Jangkauan pendeteksian	[mm]	4
------------------------	------	---



Sensor ganda AS-Interface untuk aktuatur katup pneumatik

DUAL SENSOR T5 2SI 1DO T/3G

Keping target jarak pengoperasian	[mm]	74
-----------------------------------	------	----

Kondisi pengoperasian

Suhu sekitar	[°C]	-10...50
Perlindungan		IP 67

Pengujian/persetujuan

Tanda ATEX	II 3G Ex nA IIC T6 Gc X	
Catatan tentang tanda ATEX	hanya bersama dengan casing perlindungan benturan	
EME	EN 50295	
MTTF	[ANN]	310

Klasifikasi AS-i

Versi AS-i		2.1
Mode pengalaman yang lebih luas		ya
Konfigurasi I/O AS-i	[hex]	7
Kode ID AS-i	[hex]	A.E

Data teknis

Berat	[g]	766.5
Dimensi	[mm]	55 x 60 x 35
Material	casing: PBT oranye; penutup: PC hitam; Casing perlindungan benturan: baja tahan karat	

Elemen display/pengoperasian

Display	operasi	1 x LED, hijau
	fungsi	1 x LED, kuning

Aksesori

Item dikirim	Casing perlindungan benturan	
	Pelat pemasangan: 1	
	sekrup kepala soket: 2 x M5 x 35	

Keterangan

Jumlah paket	1 buah
--------------	--------

Koneksi listrik - colokan

Konektor: 1 x M12; pengkodean: A; Bodi cetakan: baja tahan karat



Elektrischer Anschluss

1	AS-i+
3	AS-i-

AC326A



Sensor ganda AS-Interface untuk aktuator katup pneumatik

DUAL SENSOR T5 2SI 1DO T/3G

Koneksi listrik - soket

Konektor: 1 x M12; pengkodean: A; Bodi cetakan: baja tahan karat



Koneksi

Ausgänge

3	tegangan eksternal -
4	output peralihan +
1, 2, 5	nicht belegt