


AC336A



Sensor ganda AS-Interface untuk aktuator katup pneumatik

DUAL SENSOR T5 2SI 1DO T 3D

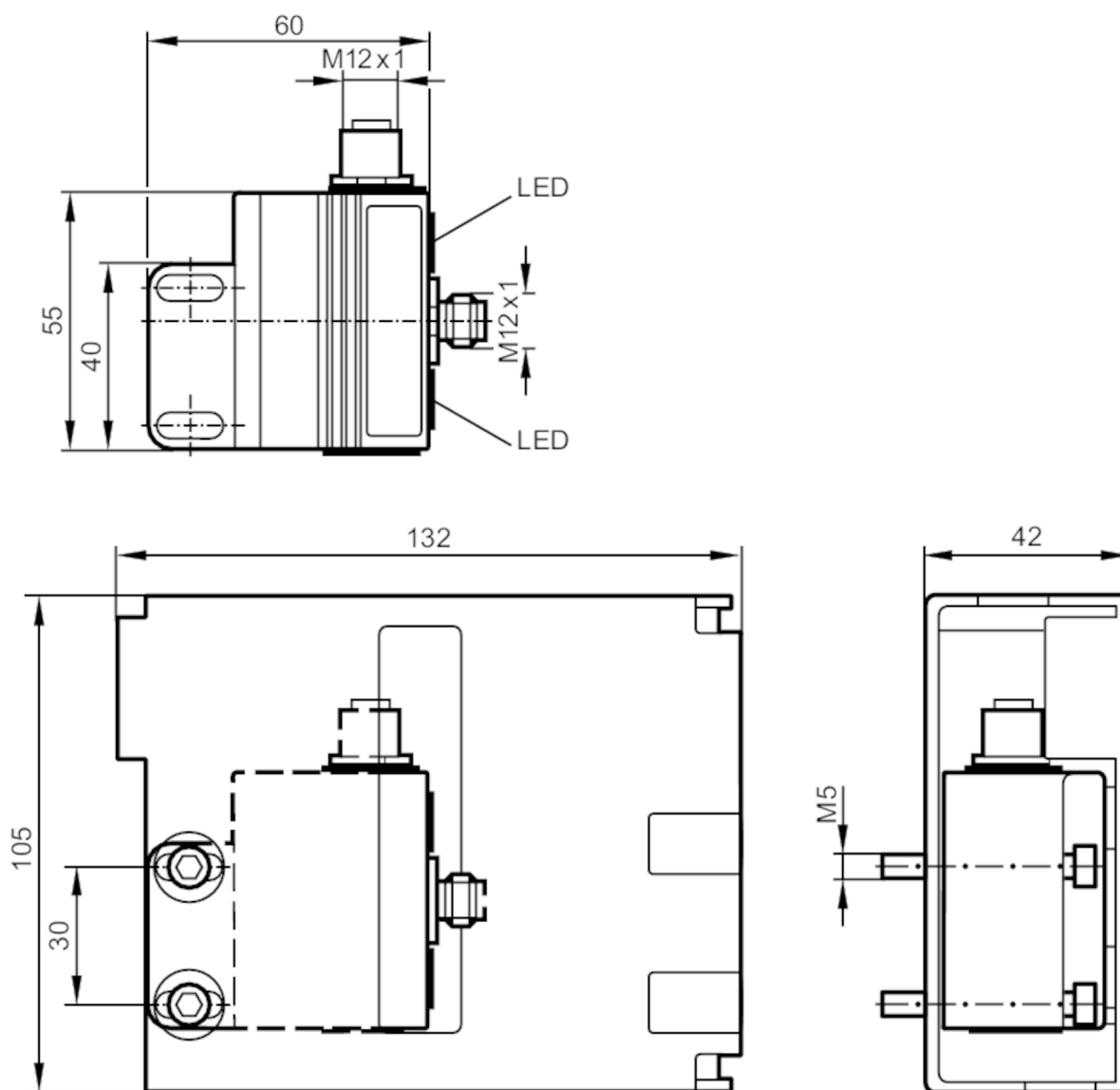

Karakteristik produk

Desain kelistrikan		AS-i
Jangkauan pendeteksian	[mm]	4
Dimensi	[mm]	55 x 60 x 35

Data kelistrikan

Tegangan pengoperasian	[V]	26.5...31.6 DC
Konsumsi arus	[mA]	160
Kelas perlindungan		III

Output

Desain kelistrikan		AS-i
--------------------	--	------



Sensor ganda AS-Interface untuk aktuatur katup pneumatik

DUAL SENSOR T5 2SI 1DO T 3D

Zona pendeteksian		
Jangkauan pendeteksian	[mm]	4
Keping target jarak pengoperasian	[mm]	74
Kondisi pengoperasian		
Suhu sekitar	[°C]	-10...50
Perlindungan		IP 5x; (jika digunakan di luar area berbahaya: IP 67)
Pengujian/persetujuan		
Tanda ATEX		 II 3D Ex tc IIIB T85°Dc IP5X X
Catatan tentang tanda ATEX		hanya bersama dengan casing perlindungan benturan
EME		EN 50295
MTTF	[ANN]	404
Klasifikasi AS-i		
Versi AS-i		2.1
Mode pengalamatan yang lebih luas		ya
Konfigurasi I/O AS-i	[hex]	7
Kode ID AS-i	[hex]	A.E
Data teknis		
Berat	[g]	779.5
Dimensi	[mm]	55 x 60 x 35
Material		casing: PBT oranye; penutup: PC hitam; Casing perlindungan benturan: baja tahan karat
Elemen display/pengoperasian		
Display	operasi	1 x LED, hijau
	fungsi	1 x LED, kuning
Aksesori		
Item dikirim		Casing perlindungan benturan
		Pelat pemasangan: 1
		sekrup kepala soket: 2 x M5 x 35
Keterangan		
Jumlah paket		1 buah
Koneksi listrik - colokan		
Konektor: 1 x M12; pengkodean: A; Bodi cetakan: baja tahan karat		
		
Elektrischer Anschluss		
1	AS-i+	
3	AS-i -	

AC336A




Sensor ganda AS-Interface untuk aktuator katup pneumatik

DUAL SENSOR T5 2SI 1DO T 3D

Koneksi listrik - soket

Konektor: 1 x M12; pengkodean: A; Bodi cetakan: baja tahan karat

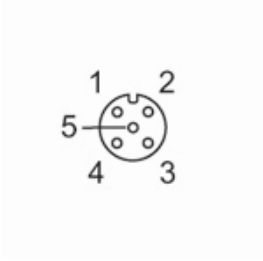

Koneksi	
Ausgänge	
3	tegangan eksternal
4	output peralihan +
1, 2, 5	nicht belegt