


ANT960



Antena RFID UHF

DTRUHFA_AERWKOTN04

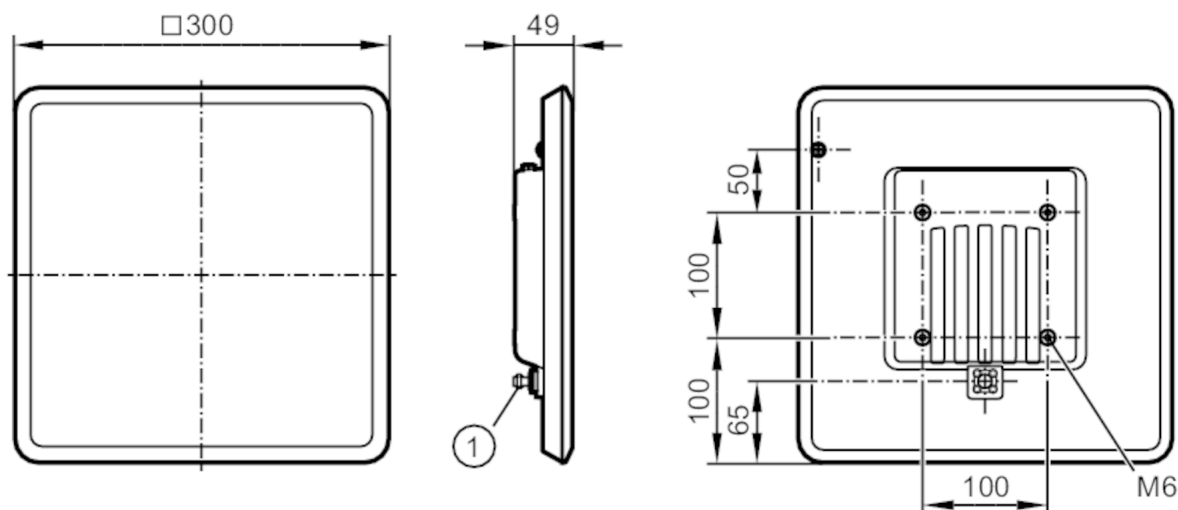

Data kelistrikan

Daya input maks.	[mW]	1000
Frekuensi pengoperasian	[MHz]	902...928 (FCC)
Koneksi antena		1; (Soket TNC)
Polarisasi		sirkular
Daya transmisi ERP	[mW]	3981
Gain antena	[dB]	8.5
Impedansi	[Ω]	50

Zona pendeteksian

Sudut bukaan	[°]	65
--------------	-----	----

Kondisi pengoperasian

Suhu sekitar	[°C]	-40...70
Suhu penyimpanan	[°C]	-40...85
Perlindungan		IP 67

Data teknis

Berat	[g]	2406.5
Casing		persegi panjang
Dimensi	[mm]	300 x 300 x 79
Material		casing: aluminium; Soket TNC: kuningan/PTFE; Tutup pelindung: plastik;

Keterangan

Jumlah paket		1 buah
--------------	--	--------