


DF1100



Modul suplai daya untuk pemutus sirkuit elektronik

Fuse/Standard/24VDC/Module

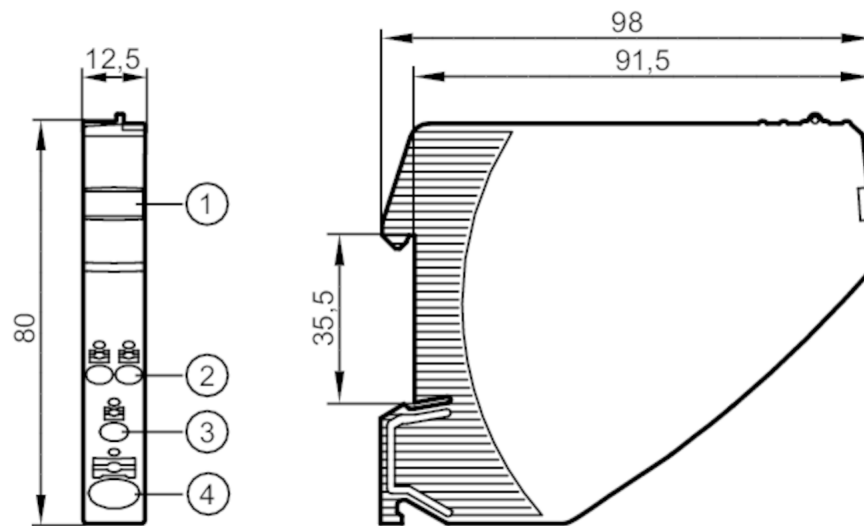

- 1 panel untuk pelabelan
- 2 terminal colok output peralihan 13/14
- 3 terminal colok 0 V
- 4 terminal colok 24 V DC



Data kelistrikan

Tegangan pengoperasian	[V]	sesuai SELV/PELV
Tegangan nominal DC	[V]	24
Tegangan input DC	[V]	19.2...30
Kelas perlindungan		III
Pelindung polaritas terbalik		ya
Waktu buffering listrik (tegangan nominal 24 V DC)	[ms]	10
Arus input (tegangan nominal 24 V DC)	[A]	40
Arus sirkuit tertutup	[mA]	10

Kondisi pengoperasian

Suhu sekitar	[°C]	-25...60
Suhu penyimpanan	[°C]	-40...70
Perlindungan		IP 20; (di bagian depan)
Tingkat kekotoran		2

Pengujian/persetujuan

EME	EN 61000-6-3	radiasi interferensi
	EN 61000-6-2	ketahanan

Data teknis

Berat	[g]	67
Dimensi	[mm]	80 x 12.5 x 98

Koneksi listrik

terminal colok:

DF1100



Modul suplai daya untuk pemutus sirkuit elektronik

Fuse/Standard/24VDC/Module

tuas/strip kontak:

Koneksi

