


Modul suplai untuk potensial ground

Supply Module GND/1x 10mm²

- 1 panel untuk pelabelan
2 terminal colok 24 V DC

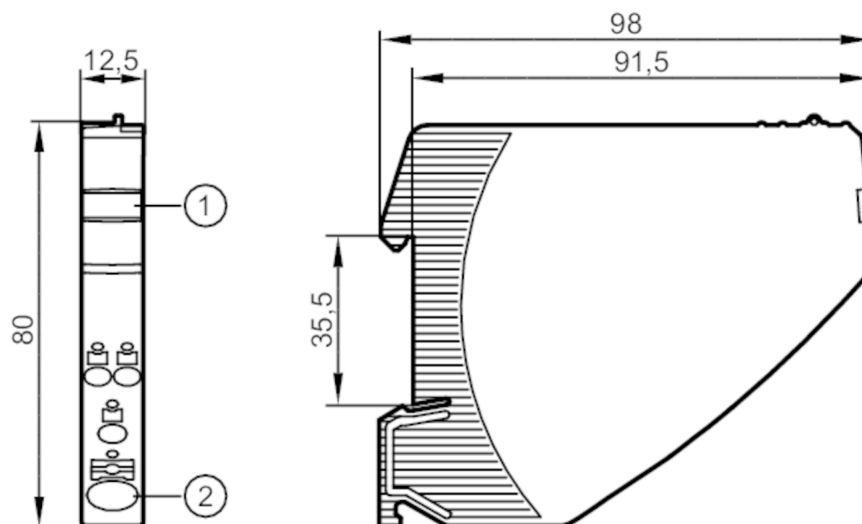

Aplikasi

Desain	modul suplai GND (1 x 10 mm ²)
--------	--

Data kelistrikan

Tegangan pengoperasian	[V]	18...30 DC
Tegangan nominal DC	[V]	24
Kelas perlindungan		III
Arus beban maks.	[A]	40

Kondisi pengoperasian

Suhu sekitar	[°C]	-25...60
Suhu penyimpanan	[°C]	-40...70
Perlindungan		IP 20; (di bagian depan)

Pengujian/persetujuan

EME	EN 61000-6-3	radiasi interferensi
	EN 61000-6-2	ketahanan

Data teknis

Berat	[g]	48.6
Tipe pemasangan		pemasangan pada rel DIN
Petunjuk pemasangan		pemasangan tali dimungkinkan
Dimensi	[mm]	80 x 12.5 x 98.5

Modul suplai untuk potensial ground

Supply Module GND/1x 10mm²

Koneksi listrik

terminal colok:

Koneksi

