


Modul distribusi untuk potensial ground

Pot.Module GND/10x 2.5mm²

- 1 panel untuk pelabelan
2 terminal colok 24 V DC

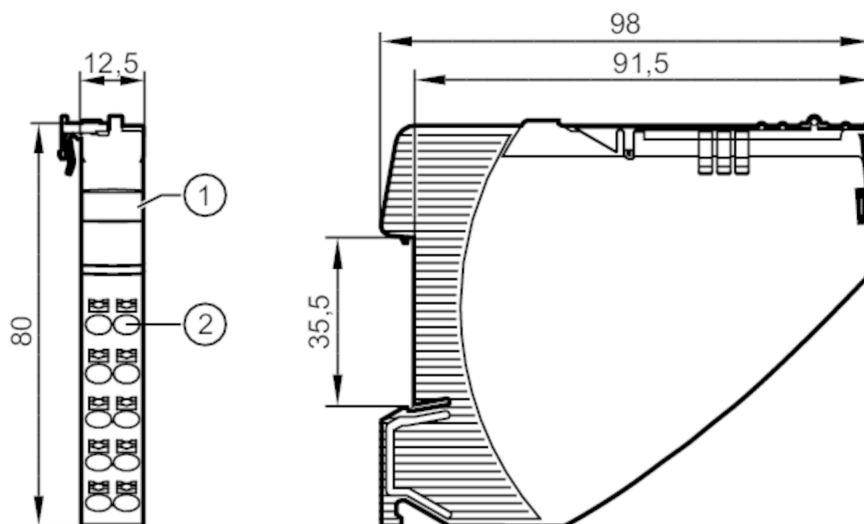

Aplikasi

Desain	modul potensial GND (10 x 2,5 mm ²)
--------	---

Data kelistrikan

Tegangan pengoperasian	[V]	18...30 DC
Tegangan nominal DC	[V]	24
Kelas perlindungan		III
Arus beban maks.	[A]	20

Kondisi pengoperasian

Suhu sekitar	[°C]	-25...60
Suhu penyimpanan	[°C]	-40...70
Perlindungan		IP 20

Pengujian/persetujuan

EME	EN 61000-6-3	radiasi interferensi
	EN 61000-6-2	ketahanan

Data teknis

Berat	[g]	62.5
Tipe pemasangan		pemasangan pada rel DIN
Petunjuk pemasangan		pemasangan tali dimungkinkan
Dimensi	[mm]	80 x 12.5 x 98.5

Modul distribusi untuk potensial ground

Pot.Module GND/10x 2.5mm2

Koneksi listrik

terminal colok:

Koneksi

