


DF3200



Modul distribusi untuk tegangan suplai

Pot.Module LOAD/2x5x 2.5mm²

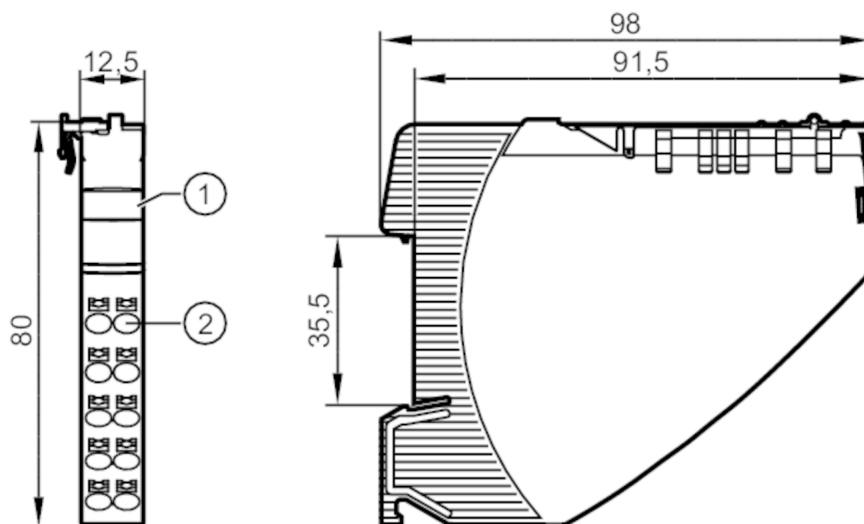

- 1 panel untuk pelabelan
2 terminal colok 24 V DC



Aplikasi

Desain modul potensial 2 x 5 x 2,5 mm²

Data kelistrikan

Tegangan pengoperasian [V]	18...30 DC
Tegangan nominal DC [V]	24
Kelas perlindungan	III
Arus beban maks. [A]	20

Kondisi pengoperasian

Suhu sekitar [°C]	-25...60
Suhu penyimpanan [°C]	-40...70
Perlindungan	IP 20

Pengujian/persetujuan

EME	EN 61000-6-3	radiasi interferensi
	EN 61000-6-2	ketahanan

Data teknis

Berat [g]	64.8
Tipe pemasangan	pemasangan pada rel DIN
Petunjuk pemasangan	pemasangan tali dimungkinkan
Dimensi [mm]	80 x 12.5 x 98.5

Modul distribusi untuk tegangan suplai

Pot.Module LOAD/2x5x 2.5mm²

Koneksi listrik

terminal colok:

Koneksi

